

## THREADED COUPLER FOR COPPER-BONDED GROUND ROD, THREADED, BRONZE, 5/8" DIA

### CATALOG NUMBER

**CR58**



### CERTIFICATIONS



### FEATURES

High-strength couplings are threaded and chamfered at both ends for easy driving

Corrosion-resistant couplings ensure permanent, low resistance copper-to-copper connections

### PRODUCT ATTRIBUTES

Material: Bronze

Ground Rod Diameter, Nominal: 5/8"


Length (L): 2.4"

Thread Size (TS): 5/8" UNC

Unit Weight: 0.23 lb

Complies With: EN IEC 62561-2

DIAGRAMS

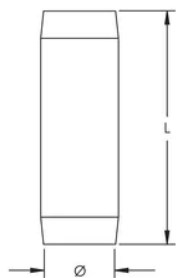

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**⚠ WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**

## THREADED COUPLER FOR COPPER-BONDED GROUND ROD, THREADED, BRONZE, 5/8" DIA

### CATALOG NUMBER

**CR58**



### CERTIFICATIONS



### FEATURES

High-strength couplings are threaded and chamfered at both ends for easy driving

Corrosion-resistant couplings ensure permanent, low resistance copper-to-copper connections

### PRODUCT ATTRIBUTES

Material: Bronze

Ground Rod Diameter, Nominal: 5/8"


Length (L): 2.4"

Thread Size (TS): 5/8" UNC

Unit Weight: 0.23 lb

Complies With: EN IEC 62561-2

DIAGRAMS

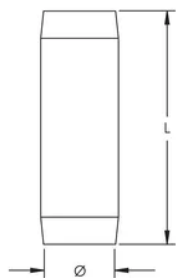

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**⚠ WARNING:** This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**