

DURAFLOOD 100




LED FLOOD LIGHT (100 WATT)

250 MH Replacement



| | |
|-------------------|------------------------------------|
| Lumens | 9,000 |
| CCT | 3000-3500K, 4000-4500K, 6000-6500K |
| CRI | > 75 |
| Beam Angle | 120° |
| Operating Voltage | 100 - 277 VAC |
| Power Consumption | 100W |
| Driver | Mean Well |
| LED Source | Bridgelux |
| Lifespan | > 50,000 Hours |
| IP Grade | IP65 |
| Body Construction | Aluminum & Toughened Glass |
| Dimensions | 11.22" x 15.12" x 7.28" |
| Weight | 12.35 lbs |

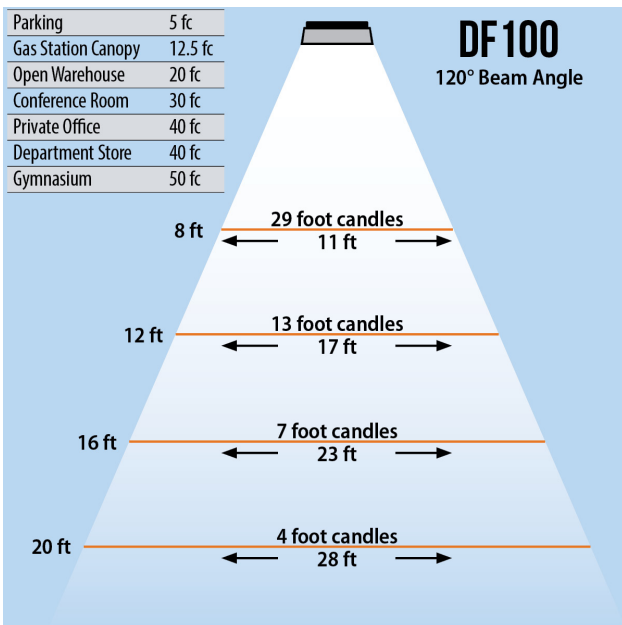

ORDER CODE Example: DF100-BRZ-6K

| Fixture | Finish | CCT |
|-----------------|-------------|-----------|
| DF100- Trunnion | BRZ- Bronze | 6K- 6000K |
| | | 4K- 4000K |
| | | 3K- 3000K |

DURAFLOOD 100




LED FLOOD LIGHT (100 WATT)

250 MH Replacement



| | |
|-------------------|------------------------------------|
| Lumens | 9,000 |
| CCT | 3000-3500K, 4000-4500K, 6000-6500K |
| CRI | > 75 |
| Beam Angle | 120° |
| Operating Voltage | 100 - 277 VAC |
| Power Consumption | 100W |
| Driver | Mean Well |
| LED Source | Bridgelux |
| Lifespan | > 50,000 Hours |
| IP Grade | IP65 |
| Body Construction | Aluminum & Toughened Glass |
| Dimensions | 11.22" x 15.12" x 7.28" |
| Weight | 12.35 lbs |

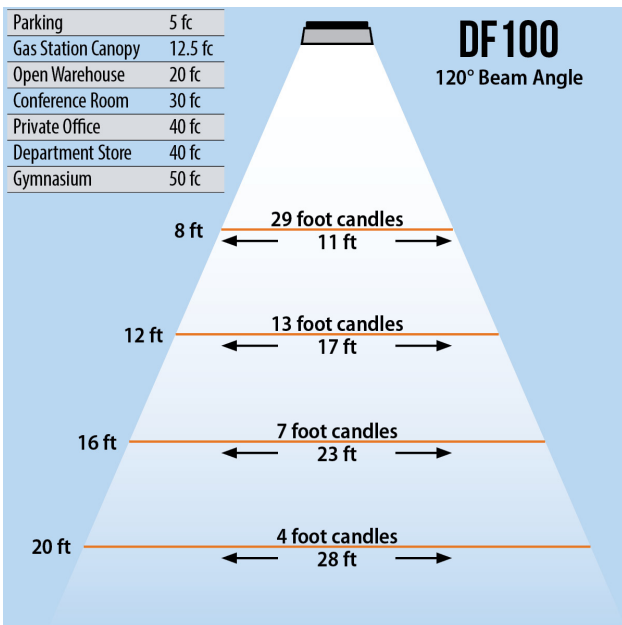

ORDER CODE Example: DF100-BRZ-6K

| Fixture | Finish | CCT |
|-----------------|-------------|-----------|
| DF100- Trunnion | BRZ- Bronze | 6K- 6000K |
| | | 4K- 4000K |
| | | 3K- 3000K |