

DURAFLOOD 20

LED FLOOD LIGHT (20 WATT)

120W PAR 38 Replacement




| | |
|-------------------|----------------------------|
| Lumens | 1,800 |
| CCT | 3000-3500K, 6000-6500K |
| CRI | > 75 |
| Beam Angle | 120° |
| Operating Voltage | 100 - 240 VAC |
| Power Consumption | 20W |
| LED Source | Bridgelux |
| Lifespan | > 50,000 Hours |
| IP Grade | IP65 |
| Body Construction | Aluminum & Toughened Glass |
| Dimensions | 7.09" x 5.51" x 5.71" |
| Weight | 2.65 lbs |



Trunnion Mount



Knuckle Mount

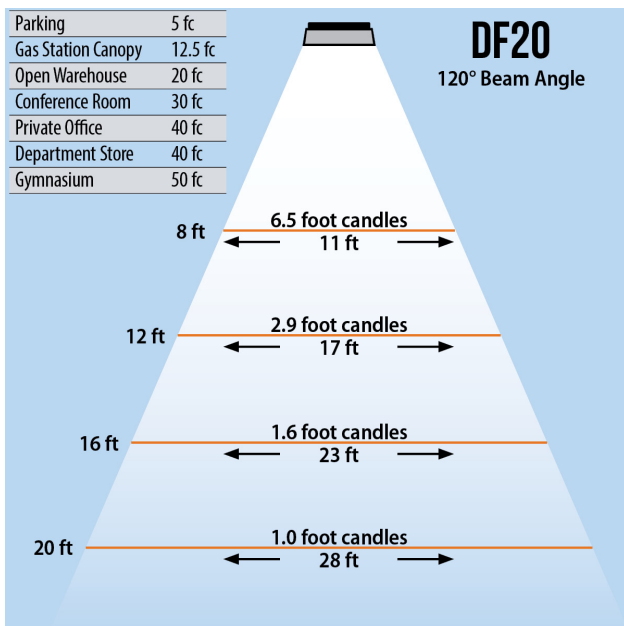

ORDER CODE Example DF20-BRZ-20W120D6K

| Fixture | Finish | Beam Angle | CCT |
|------------------|--------------|----------------|------------|
| DF200 - Trunnion | BRZ - Bronze | 20W120D - 120° | 6K - 6000K |
| DF20KM - Knuckle | | | 3K - 3000K |

DURAFLOOD 20

LED FLOOD LIGHT (20 WATT)

120W PAR 38 Replacement




| | |
|-------------------|----------------------------|
| Lumens | 1,800 |
| CCT | 3000-3500K, 6000-6500K |
| CRI | > 75 |
| Beam Angle | 120° |
| Operating Voltage | 100 - 240 VAC |
| Power Consumption | 20W |
| LED Source | Bridgelux |
| Lifespan | > 50,000 Hours |
| IP Grade | IP65 |
| Body Construction | Aluminum & Toughened Glass |
| Dimensions | 7.09" x 5.51" x 5.71" |
| Weight | 2.65 lbs |



Trunnion Mount



Knuckle Mount

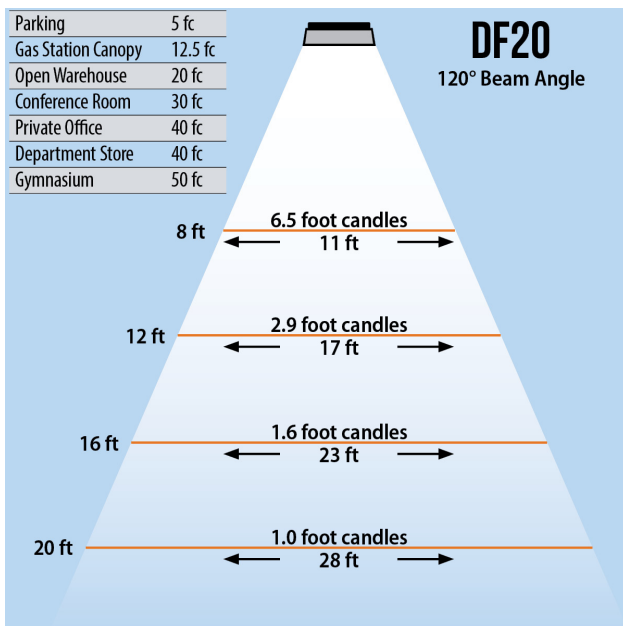

ORDER CODE Example DF20-BRZ-20W120D6K

| Fixture | Finish | Beam Angle | CCT |
|------------------|--------------|----------------|------------|
| DF200 - Trunnion | BRZ - Bronze | 20W120D - 120° | 6K - 6000K |
| DF20KM - Knuckle | | | 3K - 3000K |