

# DURAFLOOD 30

## LED FLOOD LIGHT (30 WATT)

175W PAR 38 Replacement




Lumens	2,700
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	30W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	8.86" x 7.28" x 4.96"
Weight	2.85 lbs



Trunnion Mount



Knuckle Mount

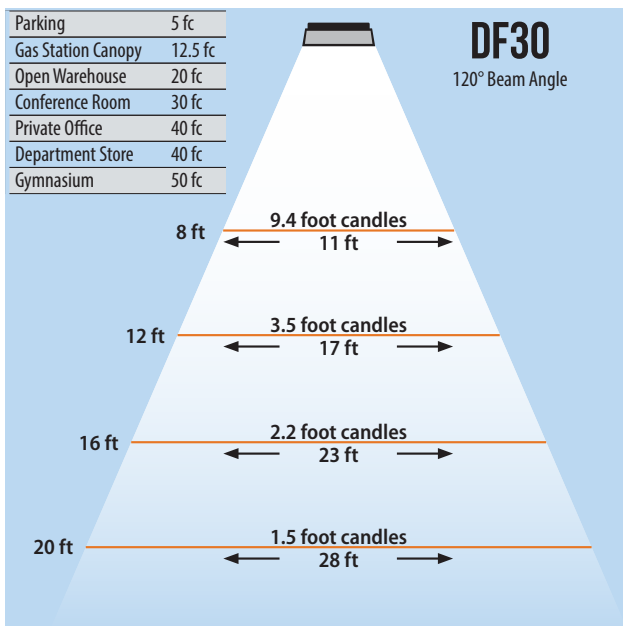

### ORDER CODE Example DF30-BRZ-30W120D6K

Fixture	Finish	Beam Angle	CCT
DF30 - Trunnion	BRZ - Bronze	30W120D - 120°	6K - 6000K
DF30KM - Knuckle			3K - 3000K

# DURAFLOOD 30

## LED FLOOD LIGHT (30 WATT)

175W PAR 38 Replacement




Lumens	2,700
CCT	3000-3500K, 6000-6500K
CRI	> 75
Beam Angle	120°
Operating Voltage	100 - 240 VAC
Power Consumption	30W
LED Source	Bridgelux
Lifespan	> 50,000 Hours
IP Grade	IP65
Body Construction	Aluminum & Toughened Glass
Dimensions	8.86" x 7.28" x 4.96"
Weight	2.85 lbs



Trunnion Mount



Knuckle Mount

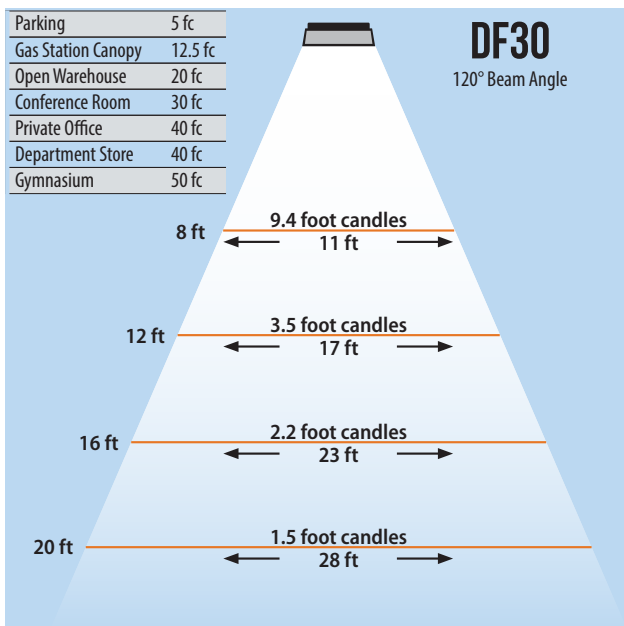

### ORDER CODE Example DF30-BRZ-30W120D6K

Fixture	Finish	Beam Angle	CCT
DF30 - Trunnion	BRZ - Bronze	30W120D - 120°	6K - 6000K
DF30KM - Knuckle			3K - 3000K