



GE
Lighting

63548 - F32T8/841/PRO/EC

F32T8/841/PRO/EC



GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T8 |
| Base | Medium Bi-Pin (G13) |
| Rated Life (NOM) | 20000.0 h |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 10.0 °C |
| Mercury Content (NOM) | 2.95 mg |
| Picograms of Mercury (NOM) | 53.64612 pg |
| Primary Application | Full Wattage |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 2925.0 |
| Nominal Initial Lumens per Watt (NOM) | 91.40625 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 85.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|------|
| Wattage (NOM) | 32.0 |
|---------------|------|

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 48.000 in(1219.2 mm) |
| Nominal Length (NOM) | 48.000 in(1219.2 mm) |
| Bulb Diameter (DIA) (NOM) | 1.000 in(25.4 mm) |

PRODUCT INFORMATION


| | |
|----------------------------------|------------------|
| Product Code | 63548 |
| Description | F32T8/841/PRO/EC |
| Standard Package | 00-Case |
| Standard Package GTIN | 10043168635483 |
| Standard Package Quantity | 36 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 36 |
| UPC | 043168635486 |



GE
Lighting

63548 - F32T8/841/PRO/EC

F32T8/841/PRO/EC

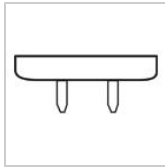

GENERAL CHARACTERISTICS

| | |
|----------------------------|-------------------------------|
| Lamp Type | Linear Fluorescent - Straight |
| | Linear |
| Bulb | T8 |
| Base | Medium Bi-Pin (G13) |
| Rated Life (NOM) | 20000.0 h |
| Bulb Material | Sodalime glass |
| Starting Temperature (MIN) | 10.0 °C |
| Mercury Content (NOM) | 2.95 mg |
| Picograms of Mercury (NOM) | 53.64612 pg |
| Primary Application | Full Wattage |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------------|----------|
| Initial Lumens (NOM) | 2925.0 |
| Nominal Initial Lumens per Watt (NOM) | 91.40625 |
| Color Temperature (NOM) | 4100.0 K |
| Color Rendering Index (CRI) (NOM) | 85.0 |

ELECTRICAL CHARACTERISTICS

| | |
|---------------|------|
| Wattage (NOM) | 32.0 |
|---------------|------|

DIMENSIONS

| | |
|------------------------------------|----------------------|
| Maximum Overall Length (MOL) (NOM) | 48.000 in(1219.2 mm) |
| Nominal Length (NOM) | 48.000 in(1219.2 mm) |
| Bulb Diameter (DIA) (NOM) | 1.000 in(25.4 mm) |

PRODUCT INFORMATION

| | |
|----------------------------------|------------------|
| Product Code | 63548 |
| Description | F32T8/841/PRO/EC |
| Standard Package | 00-Case |
| Standard Package GTIN | 10043168635483 |
| Standard Package Quantity | 36 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 36 |
| UPC | 043168635486 |