




GE  
Lighting

**13764 - F84T12/CW 15PK**

GE Cool White T12

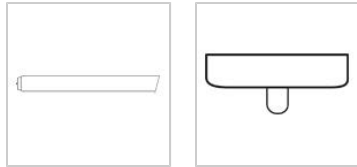

**CAUTIONS & WARNINGS**

**Caution**


- Lamp may shatter and cause injury if broken
  - Wear safety glasses and gloves when handling lamp.
  - Do not use excessive force when installing lamp.

**Warning**


- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.

**GRAPHS & CHARTS**

**Graphs\_Spectral Power Distribution**

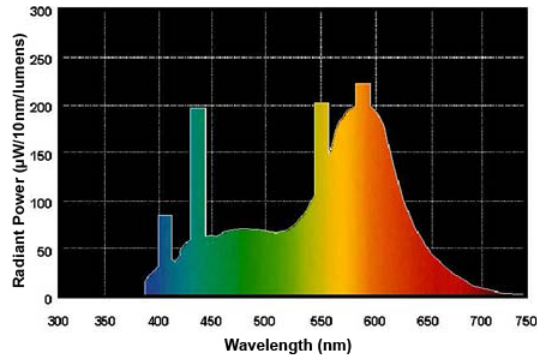

**Graphs\_Lumen Maintenance**

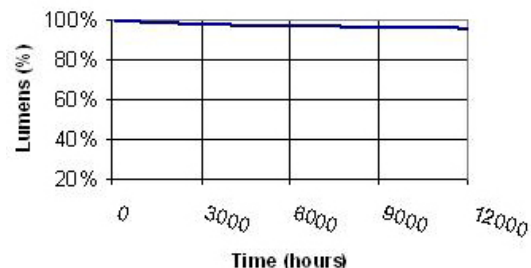

**Graphs\_Lamp Mortality**

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Soda lime
Mercury Content (NOM)	90.0 mg
Picograms of Mercury (NOM)	1536.9 pg
Primary Application	Full Wattage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	5300.0
Mean Lumens (NOM)	4880.0
Nominal Initial Lumens per Watt (NOM)	81.53846
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	60.0

**ELECTRICAL CHARACTERISTICS**


Wattage (NOM)	65.0
Cathode Resistance Ratio - Rh/ Rc (MIN)	4.25
Current Crest Factor (MAX)	1.7

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	84.000 in(2133.6 mm)
Nominal Length (NOM)	84.000 in(2133.6 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

**PRODUCT INFORMATION**

Product Code	13764
Description	F84T12/CW 15PK
Standard Package	Case
Standard Package GTIN	10043168137642
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168137645

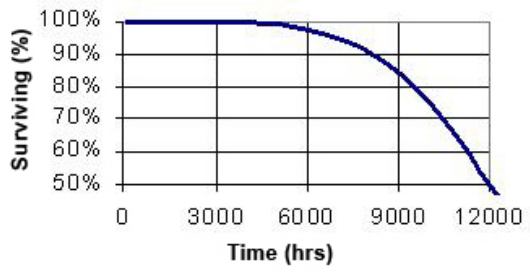




GE  
Lighting

**13764 - F84T12/CW 15PK**

GE Cool White T12

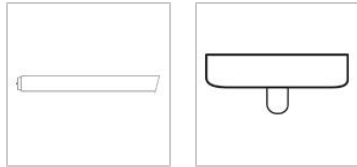

**CAUTIONS & WARNINGS**

**Caution**


- Lamp may shatter and cause injury if broken
  - Wear safety glasses and gloves when handling lamp.
  - Do not use excessive force when installing lamp.

**Warning**


- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.

**GRAPHS & CHARTS**

**Graphs\_Spectral Power Distribution**

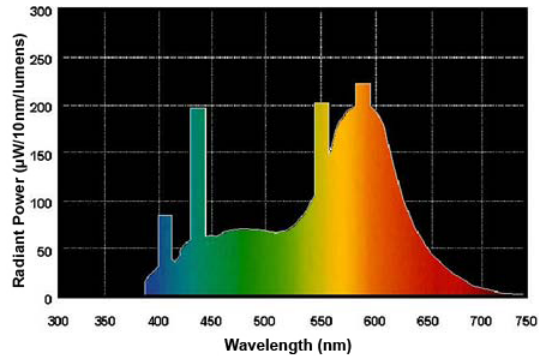

**Graphs\_Lumen Maintenance**

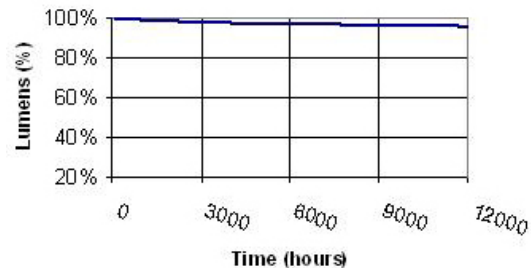

**Graphs\_Lamp Mortality**

**GENERAL CHARACTERISTICS**

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Soda lime
Mercury Content (NOM)	90.0 mg
Picograms of Mercury (NOM)	1536.9 pg
Primary Application	Full Wattage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	5300.0
Mean Lumens (NOM)	4880.0
Nominal Initial Lumens per Watt (NOM)	81.53846
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	60.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	65.0
Cathode Resistance Ratio - Rh/ Rc (MIN)	4.25
Current Crest Factor (MAX)	1.7

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	84.000 in(2133.6 mm)
Nominal Length (NOM)	84.000 in(2133.6 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

**PRODUCT INFORMATION**

Product Code	13764
Description	F84T12/CW 15PK
Standard Package	Case
Standard Package GTIN	10043168137642
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168137645

