




GE
Lighting

66858 - F96T12XL/HL41/WM

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

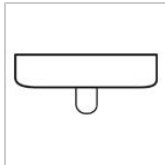

GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	15.0 mg
Picograms of Mercury (NOM)	228.1022 pg
Primary Application	Energy Saving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	5900.0
Mean Lumens (NOM)	5480.0
Nominal Initial Lumens per Watt (NOM)	98.33334
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	80.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	60.0
---------------	------

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	96.000 in(2438.4 mm)
Nominal Length (NOM)	96.000 in(2438.4 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

PRODUCT INFORMATION


Product Code	66858
Description	F96T12XL/HL41/WM
Standard Package	Case
Standard Package GTIN	10043168668580
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168668583



GE
Lighting

66858 - F96T12XL/HL41/WM

F96T12XL/HL41/WM-CIRCLEVILLE C AND I SKUS IN PULP

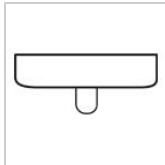

GENERAL CHARACTERISTICS

Lamp Type	Linear Fluorescent - Straight
	Linear
Bulb	T12
Base	Single Pin (Fa8)
Rated Life (NOM)	12000.0 h
Bulb Material	Sodalime glass
Starting Temperature (MIN)	15.0 °C
Mercury Content (NOM)	15.0 mg
Picograms of Mercury (NOM)	228.1022 pg
Primary Application	Energy Saving

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	5900.0
Mean Lumens (NOM)	5480.0
Nominal Initial Lumens per Watt (NOM)	98.33334
Color Temperature (NOM)	4100.0 K
Color Rendering Index (CRI) (NOM)	80.0

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	60.0
---------------	------

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	96.000 in(2438.4 mm)
Nominal Length (NOM)	96.000 in(2438.4 mm)
Bulb Diameter (DIA) (NOM)	1.500 in(38.1 mm)

PRODUCT INFORMATION

Product Code	66858
Description	F96T12XL/HL41/WM
Standard Package	Case
Standard Package GTIN	10043168668580
Standard Package Quantity	15
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	15
UPC	043168668583