

# ADJUSTABLE FLOOR BOX KITS



*with a Variety of Metal & Plastic Covers*

**Arlington**




ADJUSTS TO FINISHED FLOOR HEIGHT



FLBAF101BR



FLBAFR101BR

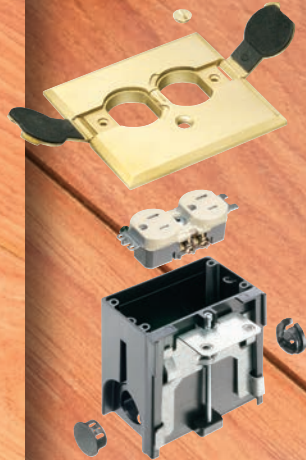

FLBAFR101MB



FLBAFR101MB



FLBA101NL



FLBAFR101NL

**EASY RECEPTACLE INSTALLATION IN FLOOR HEIGHTS UP TO 2"**

**UL LISTED • Adjusts to Floor Height up to 2"**

# ADJUSTABLE FLOOR BOX KITS

**INSTALL A RECEPTACLE IN THE FLOOR, THE EASY WAY!**


## LOW COST... EASY INSTALLATION

Arlington's UL LISTED, Adjustable **FLOOR BOXES** give installers a low cost, convenient way to install a receptacle in a new or existing floor.




We have a floor box kit to fit nearly any application or jobsite condition including our single gang *adjustable boxes*. They fit varying floor heights up to 2" in new work or retrofit.

Our adjustable box is available with non-metallic or metal covers that hide miscut flooring. Gaskets inside the cover prevent water intrusion – and threaded plugs or flip lids protect the box when it's not in use.

Non-metallic  
18.3 cu inch box

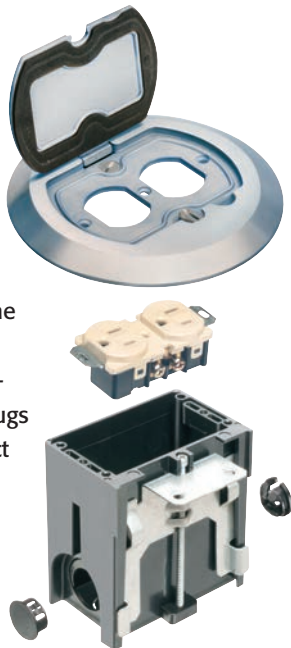

**Round or Rectangular  
Plastic, Brass or  
Nickel-plated Brass COVERS**  
with a single flip lid,  
two flip lids or two threaded plugs

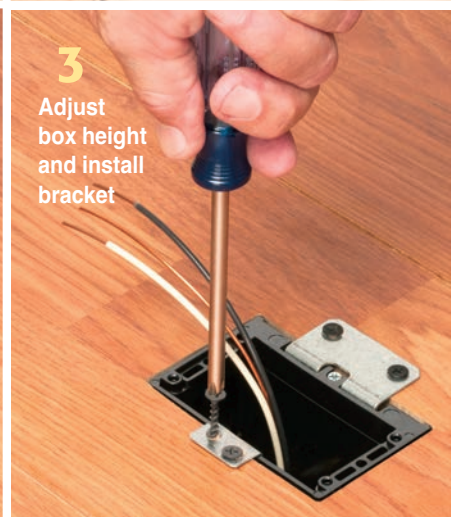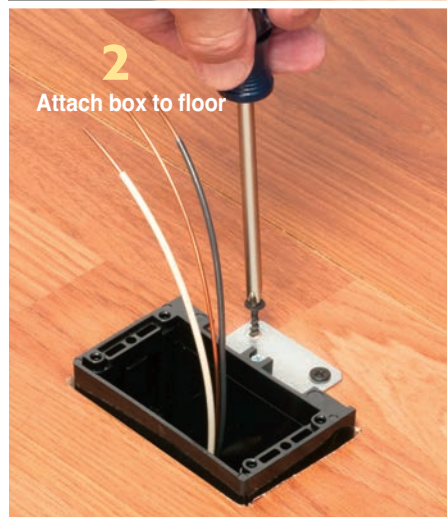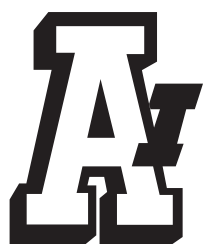

**Arlington**

# COVERS WITH SINGLE FLIP LID



FLBAFR101MB

**SINGLE Gang**  
**COVER SHAPE**



FLBAFR101NL



FLBAFR101BR



FLBAFR101MB  
Brass cover



FLBAFR101LA  
Plastic cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
ADJUSTABLE FLOOR BOX COVER COLOR/FINISH				

**METAL COVER with SINGLE FLIP LID**

FLBAFR101MB	00749	Non-metallic box, Brass single flip lid	1	4
FLBAFR101NL	00750	Non-metallic box, Nickel-plated single flip lid	1	4

**NON-METALLIC COVER with SINGLE FLIP LID**

FLBAFR101BR	00711	Non-metallic box, Brown non-metallic cover w single flip lid	1	4
FLBAFR101BL	00710	Non-metallic box, Black non-metallic cover w single flip lid	1	4
FLBAFR101CA	00712	Non-metallic box, Caramel non-metallic cover w single flip lid	1	4
FLBAFR101LA	00713	Non-metallic box, Light Almond non-metallic cover w single flip lid	1	4
FLBAFR101W	00714	Non-metallic box, White non-metallic cover w single flip lid	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" round plastic or metal cover/flip lid assembly, (2) #6-32 x 1-1/4" screws, (4) #6 drywall screws, (1) NM900 plug, (1) NM94 connector, (1) metal clip and (1) plug.

# COVERS WITH TWO FLIP LIDS



FLBAF101MB

**SINGLE Gang**  
**COVER SHAPE**



FLBAF101CA



FLBAF101NL



FLBAF101LA



FLBAF101MB  
Brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD
ADJUSTABLE FLOOR BOX COVER COLOR/FINISH				

**METAL COVER, RECTANGULAR with TWO FLIP LIDS**

FLBAF101MB	13805	Non-metallic box, Brass w two flip lids	1	4
FLBAF101NL	13806	Non-metallic box, Nickel-plated w two flip lids	1	4

**NON-METALLIC COVER, RECTANGULAR with TWO FLIP LIDS**

FLBAF101BR	04343	Non-metallic box, Brown non-metallic cover w two flip lids	1	4
FLBAF101BL	04342	Non-metallic box, Black non-metallic cover w two flip lids	1	4
FLBAF101CA	52301	Non-metallic box, Caramel non-metallic cover w two flip lids	1	4
FLBAF101LA	04341	Non-metallic box, Light Almond non-metallic cover w two flip lids	1	4
FLBAF101W	04340	Non-metallic box, White non-metallic cover w two flip lids	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 3-3/4" x 4-5/8" plastic or 4" x 4-5/8" metal cover assembly w/ two flip lids, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

# ADJUSTABLE FLOOR BOX KITS

**ADJUSTS TO FINISHED FLOOR HEIGHT**

*with a Variety of Metal & Plastic Covers*

## COVERS WITH TWO THREADED PLUGS

**SINGLE Gang**  
**COVER SHAPE**




FLBAR101LA



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	UNIT PKG	STD PKG
<b>METAL COVER, ROUND with TWO THREADED PLUGS</b>				
FLBAR101MB	52261	Non-metallic box, Brass w two threaded plugs	1	4
FLBAR101NL	52451	Non-metallic box, Nickel-plated w two threaded plugs	1	4
<b>NON-METALLIC COVER, ROUND with TWO THREADED PLUGS</b>				
FLBAR101BR	04351	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBAR101BL	04350	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBAR101LA	04349	Non-metallic box, Light Almond non-metallic cover w threaded plugs	1	4
FLBAR101W	04348	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

**SINGLE Gang**  
**COVER SHAPE**

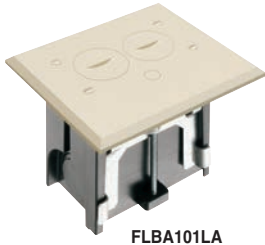

FLBA101LA



FLBA101MB



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	UNIT PKG	STD PKG
<b>METAL COVER, RECTANGULAR with TWO THREADED PLUGS</b>				
FLBA101MB	52259	Non-metallic box, Brass w two threaded plugs	1	4
FLBA101NL	52450	Non-metallic box, Nickel-plated w two threaded plugs	1	4
<b>NON-METALLIC COVER, RECTANGULAR with TWO THREADED PLUGS</b>				
FLBA101BR	04347	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBA101BL	04346	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBA101LA	04345	Non-metallic box, Light Almond non-metallic cover threaded plugs	1	4
FLBA101W	04344	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 4-1/4" x 5-1/8" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.



**Arlington**

Patented/Other patents pending

Distributed by

1 Stauffer Industrial Park. Scranton, PA 18517

800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com

# ADJUSTABLE FLOOR BOX KITS




*with a Variety of Metal & Plastic Covers*

**Arlington**



ADJUSTS TO FINISHED FLOOR HEIGHT

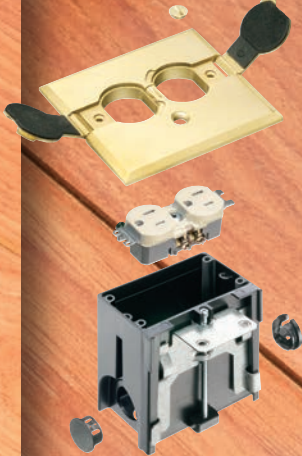

**EASY RECEPTACLE INSTALLATION IN FLOOR HEIGHTS UP TO 2"**

UL LISTED • Adjusts to Floor Height up to 2"

# ADJUSTABLE FLOOR BOX KITS

INSTALL A RECEPTACLE IN THE FLOOR, THE EASY WAY!


## LOW COST... EASY INSTALLATION

Arlington's UL LISTED, Adjustable **FLOOR BOXES** give installers a low cost, convenient way to install a receptacle in a new or existing floor.




We have a floor box kit to fit nearly any application or jobsite condition including our single gang *adjustable boxes*. They fit varying floor heights up to 2" in new work or retrofit.

Our adjustable box is available with non-metallic or metal covers that hide miscut flooring. Gaskets inside the cover prevent water intrusion – and threaded plugs or flip lids protect the box when it's not in use.

Non-metallic  
18.3 cu inch box

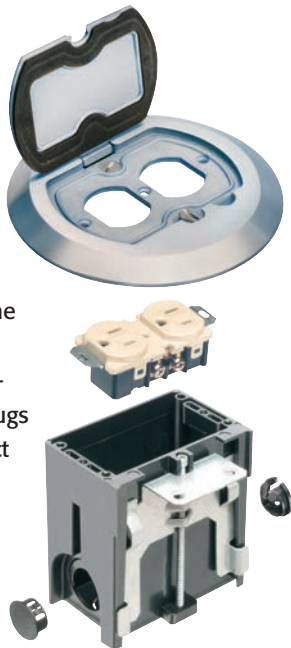

**Round or Rectangular  
Plastic, Brass or  
Nickel-plated Brass COVERS**  
with a single flip lid,  
two flip lids or two threaded plugs

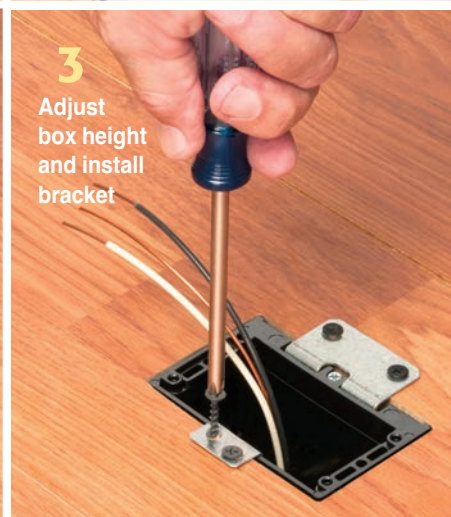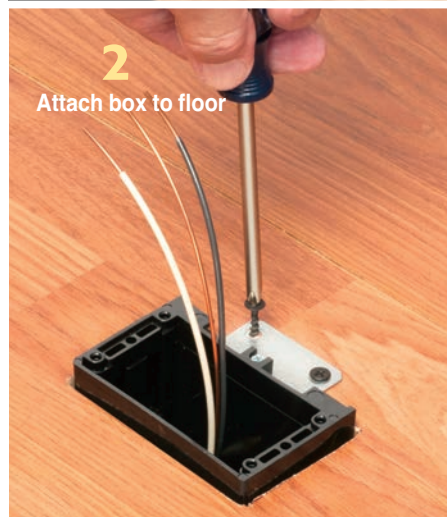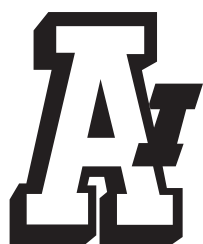

Arlington

# COVERS WITH SINGLE FLIP LID



FLBAFR101MB

**SINGLE Gang**  
**COVER SHAPE**



FLBAFR101NL



FLBAFR101BR



FLBAFR101MB  
Brass cover



FLBAFR101LA  
Plastic cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD	PKG
<b>METAL COVER with SINGLE FLIP LID</b>					
FLBAFR101MB	00749	Non-metallic box, Brass single flip lid	1		4
FLBAFR101NL	00750	Non-metallic box, Nickel-plated single flip lid	1		4
<b>NON-METALLIC COVER with SINGLE FLIP LID</b>					
FLBAFR101BR	00711	Non-metallic box, Brown non-metallic cover w single flip lid	1		4
FLBAFR101BL	00710	Non-metallic box, Black non-metallic cover w single flip lid	1		4
FLBAFR101CA	00712	Non-metallic box, Caramel non-metallic cover w single flip lid	1		4
FLBAFR101LA	00713	Non-metallic box, Light Almond non-metallic cover w single flip lid	1		4
FLBAFR101W	00714	Non-metallic box, White non-metallic cover w single flip lid	1		4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" round plastic or metal cover/flip lid assembly, (2) #6-32 x 1-1/4" screws, (4) #6 drywall screws, (1) NM900 plug, (1) NM94 connector, (1) metal clip and (1) plug.

# COVERS WITH TWO FLIP LIDS



FLBAF101MB

**SINGLE Gang**  
**COVER SHAPE**



FLBAF101CA



FLBAF101NL



FLBAF101LA



FLBAF101MB  
Brass cover

CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION	UNIT	STD	PKG
<b>METAL COVER, RECTANGULAR with TWO FLIP LIDS</b>					
FLBAF101MB	13805	Non-metallic box, Brass w two flip lids	1		4
FLBAF101NL	13806	Non-metallic box, Nickel-plated w two flip lids	1		4
<b>NON-METALLIC COVER, RECTANGULAR with TWO FLIP LIDS</b>					
FLBAF101BR	04343	Non-metallic box, Brown non-metallic cover w two flip lids	1		4
FLBAF101BL	04342	Non-metallic box, Black non-metallic cover w two flip lids	1		4
FLBAF101CA	52301	Non-metallic box, Caramel non-metallic cover w two flip lids	1		4
FLBAF101LA	04341	Non-metallic box, Light Almond non-metallic cover w two flip lids	1		4
FLBAF101W	04340	Non-metallic box, White non-metallic cover w two flip lids	1		4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 3-3/4" x 4-5/8" plastic or 4" x 4-5/8" metal cover assembly w/ two flip lids, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

# ADJUSTABLE FLOOR BOX KITS

ADJUSTS TO FINISHED FLOOR HEIGHT

with a Variety of Metal & Plastic Covers

## COVERS WITH TWO THREADED PLUGS

SINGLE Gang  
COVER SHAPE




FLBAR101LA



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	UNIT PKG	STD PKG
<b>METAL COVER, ROUND with TWO THREADED PLUGS</b>				
FLBAR101MB	52261	Non-metallic box, Brass w two threaded plugs	1	4
FLBAR101NL	52451	Non-metallic box, Nickel-plated w two threaded plugs	1	4
<b>NON-METALLIC COVER, ROUND with TWO THREADED PLUGS</b>				
FLBAR101BR	04351	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBAR101BL	04350	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBAR101LA	04349	Non-metallic box, Light Almond non-metallic cover w threaded plugs	1	4
FLBAR101W	04348	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 5-3/4" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.

SINGLE Gang  
COVER SHAPE

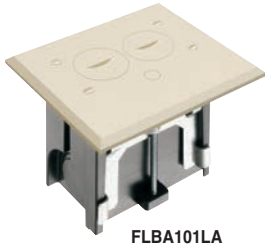

FLBA101LA



FLBA101MB



CATALOG NUMBER	UPC/DCI/NAED MFG. #018997	DESCRIPTION ADJUSTABLE FLOOR BOX COVER COLOR/FINISH	UNIT PKG	STD PKG
<b>METAL COVER, RECTANGULAR with TWO THREADED PLUGS</b>				
FLBA101MB	52259	Non-metallic box, Brass w two threaded plugs	1	4
FLBA101NL	52450	Non-metallic box, Nickel-plated w two threaded plugs	1	4
<b>NON-METALLIC COVER, RECTANGULAR with TWO THREADED PLUGS</b>				
FLBA101BR	04347	Non-metallic box, Brown non-metallic cover w threaded plugs	1	4
FLBA101BL	04346	Non-metallic box, Black non-metallic cover w threaded plugs	1	4
FLBA101LA	04345	Non-metallic box, Light Almond non-metallic cover threaded plugs	1	4
FLBA101W	04344	Non-metallic box, White non-metallic cover w threaded plugs	1	4

Includes non-metallic adjustable floor box, (1) tamper-resistant duplex receptacle, (1) 4-1/4" x 5-1/8" plastic or metal cover assembly w/ two threaded plugs, (2) #6-32 x 1" screws, (2) #6 drywall screws, (1) NM900 plug, (1) NM94 connector and (1) plug.



**Arlington**

Patented/Other patents pending

Distributed by

1 Stauffer Industrial Park. Scranton, PA 18517

800.233.4717 • www.aifittings.com • EMAIL sales@aifittings.com