



GE  
Lighting


**25186 - FLE20HT3/2/841**

GE Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

a product of  
**ecomagination**



High Color Rendering  
cUL Listed  
Energy Savings  
UL Listed

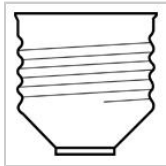

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	75.0 W
Rated Life	8000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	188 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	1200.0
Mean Lumens	1000.0
Nominal Initial Lumens per Watt	60
Color Temperature	4100.0 K
Color Rendering Index (CRI)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage	20.0
Input Voltage	120.0 V
Input Current	0.3000 A

**DIMENSIONS**

Maximum Overall Length (MOL)	4.7000 in(119.4 mm)
Nominal Length	4.700 in(119.4 mm)

**PRODUCT INFORMATION**

Product Code	25186
Description	FLE20HT3/2/841
Standard Package	Case
Standard Package GTIN	10043168251867
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168251860

**CAUTIONS & WARNINGS**

**Caution**

- Lamp may shatter and cause injury if broken
  - Remove and install by grasping only plastic portion of the lamp.

**Warning**

- Risk of Electric Shock
  - Do not open - no user serviceable parts inside.
  - Do not use where directly exposed to water.



GE  
Lighting


**25186 - FLE20HT3/2/841**

GE Spiral® T3 - Facilities; Retail Display; Hospitality; Office; Restaurant

a product of  
**ecomagination**



High Color Rendering  
cUL Listed  
Energy Savings  
UL Listed

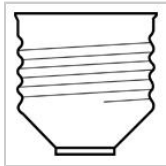

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Equivalent Wattage	75.0 W
Rated Life	8000.0 hrs
Starting Temperature (MIN)	-15.0 °C
LEED-EB MR Credit	188 picograms Hg per mean lumen hour
Primary Application	Standard;Facilities;Retail Display;Hospitality;Office;Restaurant

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	1200.0
Mean Lumens	1000.0
Nominal Initial Lumens per Watt	60
Color Temperature	4100.0 K
Color Rendering Index (CRI)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage	20.0
Input Voltage	120.0 V
Input Current	0.3000 A

**DIMENSIONS**

Maximum Overall Length (MOL)	4.7000 in(119.4 mm)
Nominal Length	4.700 in(119.4 mm)

**PRODUCT INFORMATION**

Product Code	25186
Description	FLE20HT3/2/841
Standard Package	Case
Standard Package GTIN	10043168251867
Standard Package Quantity	10
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	10
UPC	043168251860

**CAUTIONS & WARNINGS**

**Caution**

- Lamp may shatter and cause injury if broken
  - Remove and install by grasping only plastic portion of the lamp.

**Warning**

- Risk of Electric Shock
  - Do not open - no user serviceable parts inside.
  - Do not use where directly exposed to water.