




GE  
Lighting

**64802 - FLE20HT3/2SX/827**

GE energy smart® spiral® CFL 20 watt T3 spiral 1-pack

- 75 watt replacement uses only 20 watts
- Estimated yearly energy costs \$2.41 based on 3 hours per day \$0.11 per kWh
- Estimated yearly energy costs \$2.41 based on 3 hours per day \$0.11 per kWh
- Lasts 13.7 years based on 3 hours per day usage
- Lasts 13.7 years based on 3 hours per day usage
- Save money and save energy with GE energy smart® spiral® CFL bulbs. GE energy smart® bulbs use 75% less energy than standard incandescents, helping you save money on energy. And, because they last 8 times longer than a standard incandescent, you'll replace these bulbs less often. Use general purpose GE energy smart® spiral® CFL bulbs in common household fixtures like table lamps, floor lamps and bare lamp sockets
- T3 spiral shape with medium base for use in table lamps and enclosed fixtures
- \$90 in energy savings over the life of the bulb based on 3 hours per day usage

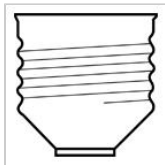

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Bulb Finish	Soft white
Equivalent Wattage (NOM)	75.0 W
Rated Life (NOM)	15000.0 h
Bulb Material	Soft glass
Total Harmonic Distortion (THD) (NOM)	150.0 %
Primary Application	Standard

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	1200.0
Mean Lumens (NOM)	960.0
Nominal Initial Lumens per Watt (NOM)	60.0
Color Temperature (NOM)	2700.0 K
Color Rendering Index (CRI) (NOM)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	20.0
Voltage (NOM)	120.0
Estimated Energy Cost per Year (NOM)	2.41

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	4.700 in(119.4 mm)
Bulb Diameter (DIA) (NOM)	0.375 in(9.5 mm)

**PRODUCT INFORMATION**

Product Code	64802
Description	FLE20HT3/2SX/827
Standard Package	Case
Standard Package GTIN	10043168648025
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168648028




GE  
Lighting

### 64802 - FLE20HT3/2SX/827

GE energy smart® spiral® CFL 20 watt T3 spiral 1-pack

- 75 watt replacement uses only 20 watts
- Estimated yearly energy costs \$2.41 based on 3 hours per day \$0.11 per kWh
- Estimated yearly energy costs \$2.41 based on 3 hours per day \$0.11 per kWh
- Lasts 13.7 years based on 3 hours per day usage
- Lasts 13.7 years based on 3 hours per day usage
- Save money and save energy with GE energy smart® spiral® CFL bulbs. GE energy smart® bulbs use 75% less energy than standard incandescents, helping you save money on energy. And, because they last 8 times longer than a standard incandescent, you'll replace these bulbs less often. Use general purpose GE energy smart® spiral® CFL bulbs in common household fixtures like table lamps, floor lamps and bare lamp sockets
- T3 spiral shape with medium base for use in table lamps and enclosed fixtures
- \$90 in energy savings over the life of the bulb based on 3 hours per day usage

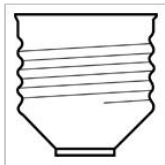

#### GENERAL CHARACTERISTICS

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	T3
Base	Medium Screw (E26)
Bulb Finish	Soft white
Equivalent Wattage (NOM)	75.0 W
Rated Life (NOM)	15000.0 h
Bulb Material	Soft glass
Total Harmonic Distortion (THD) (NOM)	150.0 %
Primary Application	Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	1200.0
Mean Lumens (NOM)	960.0
Nominal Initial Lumens per Watt (NOM)	60.0
Color Temperature (NOM)	2700.0 K
Color Rendering Index (CRI) (NOM)	82.0

#### ELECTRICAL CHARACTERISTICS

Wattage (NOM)	20.0
Voltage (NOM)	120.0
Estimated Energy Cost per Year (NOM)	2.41

#### DIMENSIONS

Maximum Overall Length (MOL) (NOM)	4.700 in(119.4 mm)
Bulb Diameter (DIA) (NOM)	0.375 in(9.5 mm)

#### PRODUCT INFORMATION

Product Code	64802
Description	FLE20HT3/2SX/827
Standard Package	Case
Standard Package GTIN	10043168648025
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168648028