




GE  
Lighting

**66666 - FLE26/2DMR40/BX**

GE energy smart® dimming CFL 26 watt R40 floodlight 1-pack

- \$56 in energy savings over the life of the bulb based on 3 hours per day usage
- Energy Star Qualified
- Estimated yearly energy costs \$3.13 based on 3 hours per day \$0.11 per kWh
- Lasts 7.3 years based on 3 hours per day usage
- R40 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting
- The GE energy smart® indoor floodlight CFLs feature a GE Spiral® bulb on the inside that uses 75% less energy and lasts up to 5 times longer than incandescent indoor reflectors. These bulbs' funnel shape help direct light where it is needed better than a standard CFL or incandescent bulb. Use GE energy smart® indoor floodlight CFLs in indoor recessed track and recessed fixtures to create broad beams of light in any room or space
- 90 watt replacement uses only 26 watts

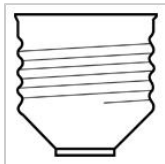

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	R40
Base	Medium Screw (E26)
Bulb Finish	Soft white
Equivalent Wattage (NOM)	100.0 W
Rated Life (NOM)	8000.0 h
Bulb Material	Soft glass
Dimming Capability	Yes
Additional Info	GE energy smart® CFL R40 90W replacement
Primary Application	Turn Signal, Front

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	1300.0
Nominal Initial Lumens per Watt (NOM)	50.0
Color Temperature (NOM)	2700.0 K
Color Rendering Index (CRI) (NOM)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	26.0
Voltage (NOM)	120.0

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	6.700 in(170.2 mm)
Bulb Diameter (DIA) (NOM)	5.000 in(127.0 mm)

**PRODUCT INFORMATION**

Product Code	66666
Description	FLE26/2DMR40/BX
Standard Package	Case
Standard Package GTIN	10043168666661
Standard Package Quantity	1
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	3
UPC	43168666664




GE  
Lighting

**66666 - FLE26/2DMR40/BX**

**GE energy smart® dimming CFL 26 watt R40 floodlight 1-pack**

- \$56 in energy savings over the life of the bulb based on 3 hours per day usage
- Energy Star Qualified
- Estimated yearly energy costs \$3.13 based on 3 hours per day \$0.11 per kWh
- Lasts 7.3 years based on 3 hours per day usage
- R40 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting
- The GE energy smart® indoor floodlight CFLs feature a GE Spiral® bulb on the inside that uses 75% less energy and lasts up to 5 times longer than incandescent indoor reflectors. These bulbs' funnel shape help direct light where it is needed better than a standard CFL or incandescent bulb. Use GE energy smart® indoor floodlight CFLs in indoor recessed track and recessed fixtures to create broad beams of light in any room or space
- 90 watt replacement uses only 26 watts

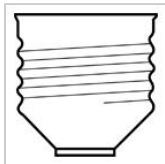

**GENERAL CHARACTERISTICS**

Lamp Type	Compact Fluorescent - Self-Ballasted
Bulb	R40
Base	Medium Screw (E26)
Bulb Finish	Soft white
Equivalent Wattage (NOM)	100.0 W
Rated Life (NOM)	8000.0 h
Bulb Material	Soft glass
Dimming Capability	Yes
Additional Info	GE energy smart® CFL R40 90W replacement
Primary Application	Turn Signal, Front

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens (NOM)	1300.0
Nominal Initial Lumens per Watt (NOM)	50.0
Color Temperature (NOM)	2700.0 K
Color Rendering Index (CRI) (NOM)	82.0

**ELECTRICAL CHARACTERISTICS**

Wattage (NOM)	26.0
Voltage (NOM)	120.0

**DIMENSIONS**

Maximum Overall Length (MOL) (NOM)	6.700 in(170.2 mm)
Bulb Diameter (DIA) (NOM)	5.000 in(127.0 mm)

**PRODUCT INFORMATION**

Product Code	66666
Description	FLE26/2DMR40/BX
Standard Package	Case
Standard Package GTIN	10043168666661
Standard Package Quantity	1
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	3
UPC	43168666664