



FLJ : LED FLOOD LIGHT MINI

DESCRIPTION

- Cost-effective solid state solution for flood light applications
- Instant-on with no warmup
- Compact and stylish design with yoke or knuckle mount

LISTINGS

- UL Listed for wet locations
- IP65 Rated
- DesignLights Consortium® Qualified - meets DLC requirements for efficacy and lumen maintenance

LED CHARACTERISTICS

- Rated lifetime L70: 50,000 hours
- 3000K, 5000K CCT
- CRI: 80+

ELECTRICAL

- Input voltage: 120-277V
- Power Factor: >.90
- THD: <20%

CONSTRUCTION

- Aluminum heat sink with durable outdoor powder coating
- Impact-resistant polycarbonate lens
- -40°F to 122°F (-40°C to 50°C) operating temperature

WARRANTY

- 5 year limited warranty; see eiko.com for warranty details

| | |
|----------------|---------|
| project name | type |
| catalog number | |
| comments | voltage |
| approved by | date |



12W - yoke



12W - knuckle



30W - yoke



30W - knuckle



50W - yoke



50W - knuckle

APPLICATIONS

- Building Facades
- Safety / Security
- Signs
- Entryways



ORDERING INFORMATION

EXAMPLE: FLJ-3C-30K-K-U


| Model | Package | CCT | Mount | Voltage |
|----------------------------|---|--|---------------------------------------|---------------------|
| FLJ : LED Flood Light Mini | 1C - 12W; 1,270/1,423 lm 3C - 30W; 3,135/3,538 lm 5C - 50W; 5,411/6,103 lm | 30K - 3000K 50K - 5000K | Y - Yoke K - Knuckle | U - 100-277V |

PERFORMANCE SUMMARY

| Order Code | Item # | Watts | Lumens | CCT | CRI | Volts | Mount | DLC |
|------------|----------------|-------|--------|-------|-----|----------|---------|-----|
| 09618 | FLJ-1C-30K-Y-U | 12W | 1,270 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09619 | FLJ-1C-30K-K-U | 12W | 1,270 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09611 | FLJ-1C-50K-Y-U | 12W | 1,423 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09612 | FLJ-1C-50K-K-U | 12W | 1,423 | 5000K | 80+ | 100-277V | Knuckle | ✓ |
| 09613 | FLJ-3C-30K-Y-U | 30W | 3,135 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09614 | FLJ-3C-30K-K-U | 30W | 3,135 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09615 | FLJ-3C-50K-Y-U | 30W | 3,538 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09623 | FLJ-3C-50K-K-U | 30W | 3,538 | 5000K | 80+ | 100-277V | Knuckle | ✓ |
| 09620 | FLJ-5C-30K-Y-U | 50W | 5,411 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09621 | FLJ-5C-30K-K-U | 50W | 5,411 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09616 | FLJ-5C-50K-Y-U | 50W | 6,103 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09617 | FLJ-5C-50K-K-U | 50W | 6,103 | 5000K | 80+ | 100-277V | Knuckle | ✓ |

✓DesignLights Consortium® Qualified

DIMENSIONS

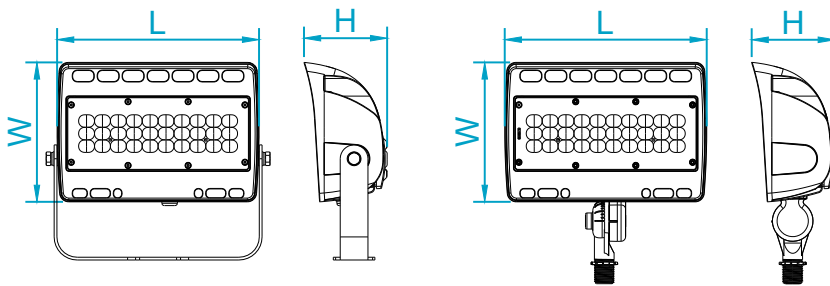


| Model | Dimensions L*W*H |
|----------|---|
| 1C - 12W | 120 x 83 x 66mm 4.75 x 3.25 x 2.625" |
| 3C - 30W | 175 x 121 x 78mm 6.875 x 4.75 x 3.125" |
| 5C - 50W | 219 x 151 x 90mm 8.625 x 6 x 3.5" |

AVAILABLE ACCESSORIES

| Order Code | Item # | Description |
|------------|------------|---|
| 09966 | PC1-4036-U | Photocell, Flush Mount, 120-277V |
| 09967 | PC1-4136-U | Photocell, Stem Mount, Side Lens, 120-277V |
| 09968 | PC1-4236-U | Photocell, Stem Swivel Mount, Side Lens, 120-277V |
| 09969 | PC1-4736-U | Photocell, Stem Swivel Mount, Top Lens, 120-277V |

PHOTOMETRICS (50W)

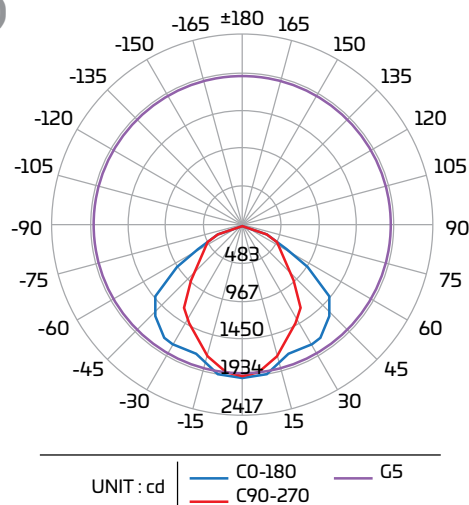



FLJ : LED FLOOD LIGHT MINI

DESCRIPTION

- Cost-effective solid state solution for flood light applications
- Instant-on with no warmup
- Compact and stylish design with yoke or knuckle mount

LISTINGS

- UL Listed for wet locations
- IP65 Rated
- DesignLights Consortium® Qualified - meets DLC requirements for efficacy and lumen maintenance

LED CHARACTERISTICS

- Rated lifetime L70: 50,000 hours
- 3000K, 5000K CCT
- CRI: 80+

ELECTRICAL

- Input voltage: 120-277V
- Power Factor: >.90
- THD: <20%

CONSTRUCTION

- Aluminum heat sink with durable outdoor powder coating
- Impact-resistant polycarbonate lens
- -40°F to 122°F (-40°C to 50°C) operating temperature

WARRANTY

- 5 year limited warranty; see eiko.com for warranty details

| | |
|----------------|---------|
| project name | type |
| catalog number | |
| comments | voltage |
| approved by | date |



12W - yoke



12W - knuckle



30W - yoke



30W - knuckle



50W - yoke



50W - knuckle

APPLICATIONS

- Building Facades
- Safety / Security
- Signs
- Entryways



ORDERING INFORMATION

EXAMPLE: FLJ-3C-30K-K-U


| Model | Package | CCT | Mount | Voltage |
|----------------------------|---|--|---------------------------------------|---------------------|
| FLJ : LED Flood Light Mini | 1C - 12W; 1,270/1,423 lm 3C - 30W; 3,135/3,538 lm 5C - 50W; 5,411/6,103 lm | 30K - 3000K 50K - 5000K | Y - Yoke K - Knuckle | U - 100-277V |

PERFORMANCE SUMMARY

| Order Code | Item # | Watts | Lumens | CCT | CRI | Volts | Mount | DLC |
|------------|----------------|-------|--------|-------|-----|----------|---------|-----|
| 09618 | FLJ-1C-30K-Y-U | 12W | 1,270 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09619 | FLJ-1C-30K-K-U | 12W | 1,270 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09611 | FLJ-1C-50K-Y-U | 12W | 1,423 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09612 | FLJ-1C-50K-K-U | 12W | 1,423 | 5000K | 80+ | 100-277V | Knuckle | ✓ |
| 09613 | FLJ-3C-30K-Y-U | 30W | 3,135 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09614 | FLJ-3C-30K-K-U | 30W | 3,135 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09615 | FLJ-3C-50K-Y-U | 30W | 3,538 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09623 | FLJ-3C-50K-K-U | 30W | 3,538 | 5000K | 80+ | 100-277V | Knuckle | ✓ |
| 09620 | FLJ-5C-30K-Y-U | 50W | 5,411 | 3000K | 80+ | 100-277V | Yoke | ✓ |
| 09621 | FLJ-5C-30K-K-U | 50W | 5,411 | 3000K | 80+ | 100-277V | Knuckle | ✓ |
| 09616 | FLJ-5C-50K-Y-U | 50W | 6,103 | 5000K | 80+ | 100-277V | Yoke | ✓ |
| 09617 | FLJ-5C-50K-K-U | 50W | 6,103 | 5000K | 80+ | 100-277V | Knuckle | ✓ |

✓DesignLights Consortium® Qualified

DIMENSIONS

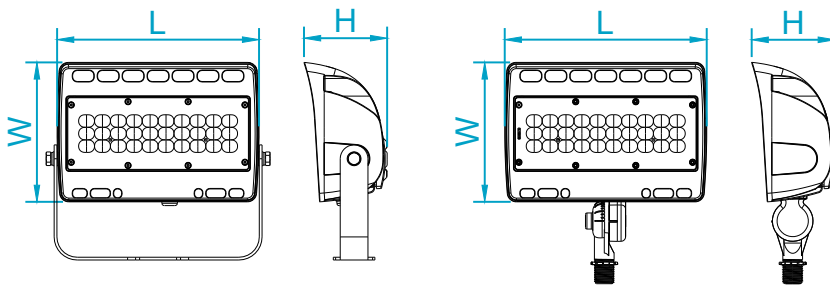

| Model | Dimensions L*W*H |
|----------|---|
| 1C - 12W | 120 x 83 x 66mm 4.75 x 3.25 x 2.625" |
| 3C - 30W | 175 x 121 x 78mm 6.875 x 4.75 x 3.125" |
| 5C - 50W | 219 x 151 x 90mm 8.625 x 6 x 3.5" |

AVAILABLE ACCESSORIES

| Order Code | Item # | Description |
|------------|------------|---|
| 09966 | PC1-4036-U | Photocell, Flush Mount, 120-277V |
| 09967 | PC1-4136-U | Photocell, Stem Mount, Side Lens, 120-277V |
| 09968 | PC1-4236-U | Photocell, Stem Swivel Mount, Side Lens, 120-277V |
| 09969 | PC1-4736-U | Photocell, Stem Swivel Mount, Top Lens, 120-277V |

PHOTOMETRICS (50W)

