

FLS


120V

TECHNICAL SPECIFICATIONS:

- :: Die-cast aluminum with powder coat finish
- :: Cover type: Transparent PC
- :: White Reflector
- :: Driver: Non-dimmable driver
- :: 13" #18 AWG stranded wires
- :: Power: 10W
- :: Lumens: 950LM
- :: Light Efficiency: 95LM/W
- :: Voltage: 100~130V, 50/60Hz
- :: CRI: >80
- :: Source: COB
- :: Beam Angle: 100°
- :: IP Rating: Wet Location
- :: Rotating directional hood

APPLICATIONS:

- :: A modern replacement for weatherproof PAR38 lamp holders and 100W quartz fixtures

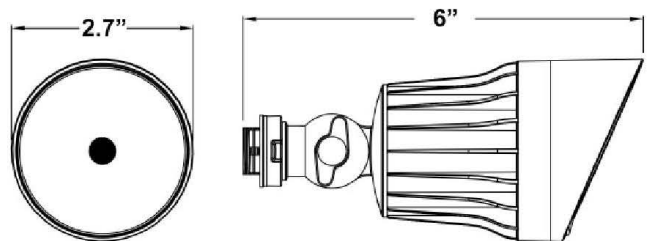

120V LED WEATHERPROOF FLOOD HEAD

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	FINISH	DIMENSIONS
FLS-10W-30K-BR	10W	950LM	3000K	Bronze	6"(L) x 2.7"(D)
FLS-10W-50K-BR	10W	950LM	5000K	Bronze	
FLS-10W-30K-WH	10W	950LM	3000K	White	
FLS-10W-50K-WH	10W	950LM	5000K	White	



A26

120V LED FLOOD HEAD

FLS


120V

TECHNICAL SPECIFICATIONS:

- :: Die-cast aluminum with powder coat finish
- :: Cover type: Transparent PC
- :: White Reflector
- :: Driver: Non-dimmable driver
- :: 13" #18 AWG stranded wires
- :: Power: 10W
- :: Lumens: 950LM
- :: Light Efficiency: 95LM/W
- :: Voltage: 100~130V, 50/60Hz
- :: CRI: >80
- :: Source: COB
- :: Beam Angle: 100°
- :: IP Rating: Wet Location
- :: Rotating directional hood

APPLICATIONS:

- :: A modern replacement for weatherproof PAR38 lamp holders and 100W quartz fixtures

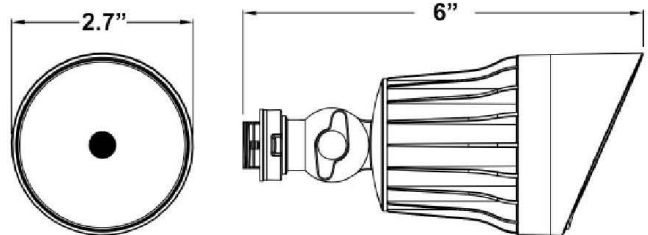

120V LED WEATHERPROOF FLOOD HEAD

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	FINISH	DIMENSIONS
FLS-10W-30K-BR	10W	950LM	3000K	Bronze	6"(L) x 2.7"(D)
FLS-10W-50K-BR	10W	950LM	5000K	Bronze	
FLS-10W-30K-WH	10W	950LM	3000K	White	
FLS-10W-50K-WH	10W	950LM	5000K	White	

