

# LED FSL & FML Decorative Floodlights




## NEW Architectural Decorative LED Floodlights!

Hubbell Outdoor Lighting's compact, sleek and stylish floodlights provide energy-efficient floodlighting solutions with a wide distribution. These powerful floodlights are available in two sizes, making them a versatile choice for many floodlighting applications: safety/security, facade, area and signs.

## Key Features & Benefits

### FSL-7


- Ultra-compact size measuring only 4.50" x 7.49" x 4.03"
- Meets DesignLights Consortium (DLC) qualifications
- IP66 and wet location listed
- Vented housing isolates LED module from driver maximizing product life and performance
- Wide flood NEMA 6 x 6 distribution for general purpose flood and facade lighting
- Traditional 1/2" x 14 NPS threaded adjustable knuckle mounting
- Rugged die-cast aluminum housing with dark bronze finish
- High impact UV stabilized acrylic outer lens protects LEDs and allows for cleaning and debris removal
- 120-277V 50/60 Hz operation (PC version 120V only)
- Visor and vandal shield available

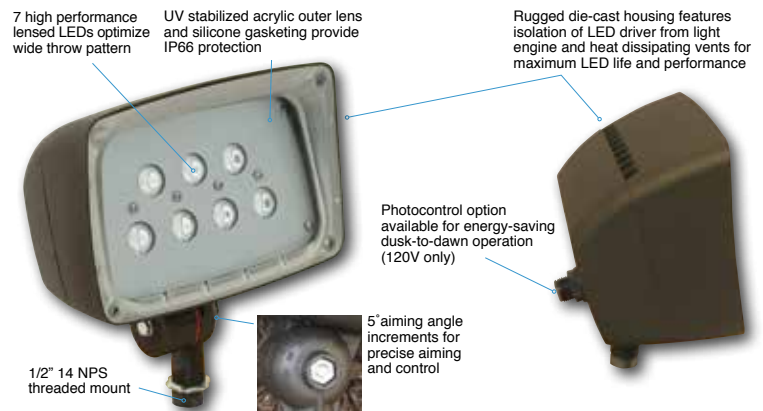

Catalog Number / UPC • EXPRESSLINE (version with PC1 suffix includes 120V photocontrol)	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Max Candle Power	Beam Pattern	CCT	Voltage	Drive Current
	MH	HPS	CFL								
FSL-7 / 785988030675	100w	100w	42w	2040	26.5	77	1450	Wide	5100K	120-277V	1050mA
FSL-7-PC1 / 785988030736											


### FML-14

- Compact size measuring only 6.68" x 9.63" x 4.53"
- Meets DesignLights Consortium (DLC) qualifications
- IP65 and wet location listed
- Vented housing isolates LED module from driver maximizing product life and performance
- Wide flood NEMA 6 x 6 distribution for general purpose flood and facade lighting
- Traditional 1/2" x 14 NPS threaded adjustable knuckle mounting
- Rugged die-cast aluminum housing with dark bronze finish
- High impact UV stabilized acrylic outer lens protects LEDs and allows for cleaning and debris removal
- 120-277V 50/60 Hz operation (PC version 120V only)
- Visor and vandal shield available

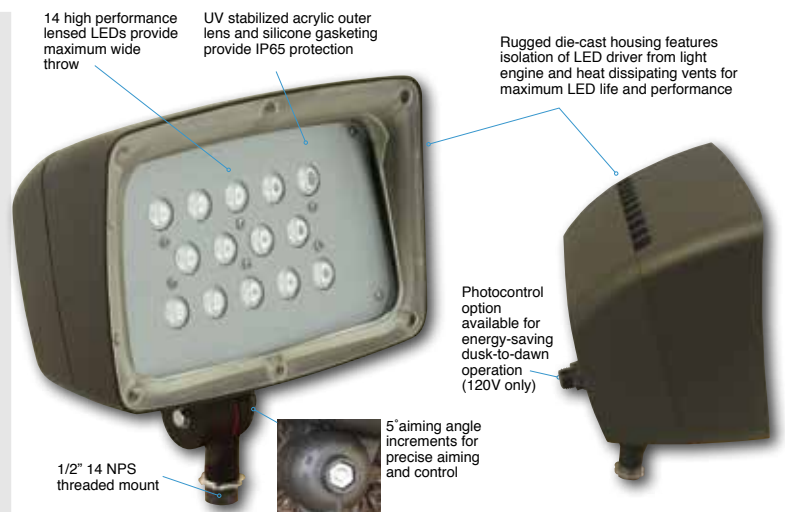


Catalog Number / UPC • EXPRESSLINE (version with PC1 suffix includes 120V photocontrol)	Equivalency			Delivered Lumens	System Watts	Lumens Per Watt	Max Candle Power	Beam Pattern	CCT	Voltage	Drive Current
	MH	HPS	CFL								
FML-14 / 785988030682	150w	150w	2x42w	4285	53	81	2805	Wide	5100K	120-277V	1050mA
FML-14-PCU / 785988030743											

## PERFORMANCE

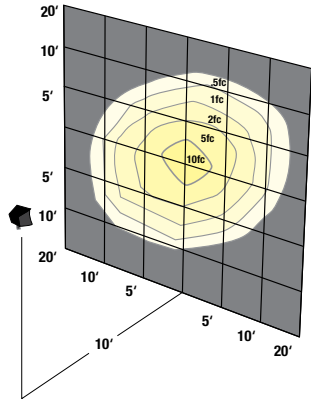

FSL-7

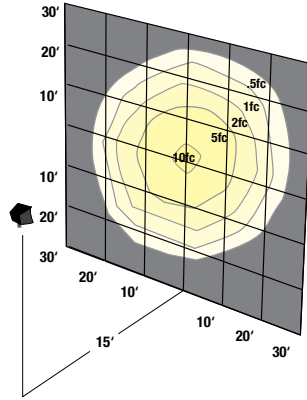


FML-14

## ORDERING INFORMATION

Catalog Number	Mount	Beam Pattern	Wattage	Drive Current	Voltage	Color Temperature	Lumens	LPW	Weight lbs. (kg)
FSL-7	1/2" thread	Wide	26.5	1050mA	120V-277V	5100K	2040	77	5.8 (2.66)
FSL-7-PC1	1/2" thread	Wide	26.5	1050mA	120V	5100K	2040	77	5.8 (2.66)
FML-14	1/2" thread	Wide	53	1050mA	120V-277V	5100K	4285	81	8.3 (3.81)
FML-14-PCU	1/2" thread	Wide	53	1050mA	120V	5100K	4285	81	8.3 (3.81)




## DIMENSIONS

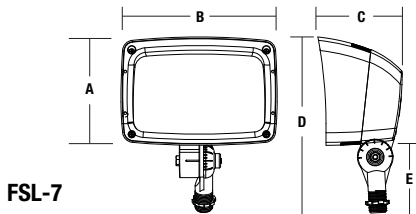

FSL-7

A	B	C
4.5"	7.49"	4.03"
114 mm	190 mm	102 mm

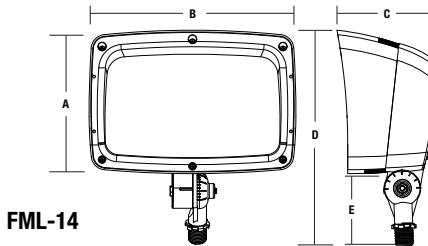

FML-14

A	B	C
6.68"	9.63"	4.53"
169 mm	244 mm	115 mm

## ACCESSORIES - Order Separately

Catalog Number	Description
FSL-SPC	Polycarbonate shield/lens (Replaces existing acrylic lens)
FSL-VISOR	Top/Bottom visor (Tap holes in lens frame for field installation)

Catalog Number	Description
FML-SPC	Polycarbonate shield/lens (Replaces existing acrylic lens)
FML-VISOR	Top/Bottom visor (Tap holes in lens frame for field installation)

## SHIPPING DIMENSIONS

Catalog Number	G.W(kg)/CTN	Carton Dimensions		
		Length Inch (cm)	Width Inch (cm)	Height Inch (cm)
FSL-7 (Single carton 1 pc.)	2.66	9.45"	7.87"	6.69"
FSL-7 (Master carton 2 pcs.)	5.31	16.54"	10.04"	7.68"

Catalog Number	G.W(kg)/CTN	Carton Dimensions		
		Length Inch (cm)	Width Inch (cm)	Height Inch (cm)
FML-14 (Single carton 1 pc.)	3.81	11.81"	9.45"	7.48"
FML-14 (Master carton 2 pcs.)	7.61	19.69"	12.40"	8.46"

Carton dimensions for shipping purposes only.