



**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GAR1826  
 7818102350033  
 4-2/0CU 2IPS  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in)	3.69
Length (in)	1.56
Height (in)	4.25
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
B Length (in)	2.75
Width (Fraction)	3-3/4
Height (Fraction) (in)	4-1/4

**General**

**Product Description**  
 Mechanical Grounding Connector,  
 Cable to Rod or Pipe, 4 AWG  
 (Sol)-2/0 AWG (Str), 2" Pipe,  
 2" -2-3/8" Rod, Bright Dipped

**Other**

Type of U Bolt 257

**Approvals / Certifications**

UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y

**Conductor(s)**

Copper Tube Size (SCH40) - Range	2 IPS IPS
Rod Size (Range)	2 in-2 3/8 in
Copper Solid Size (Range)	4 AWG-3/0 AWG
Copper Stranded (Range)	5 AWG-2/0 AWG
Rebar Size (Range)	N/A

**Physical**

Type of Hardware	DURIUM® Silicon Bronze
Installation Torque	240
Type of Plating	Bright Dipped
Plated (Yes or No)	N
Product Material	Copper Alloy

**Documentation**

For further technical assistance, please contact us


**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175

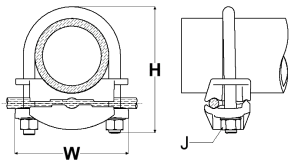

**BURNDY Catalog Number**  
**UPC Number**  
**Description**  
**Status**

GAR1826  
 7818102350033  
 4-2/0CU 2IPS  
 Active

**Web Use**  
 BURNDY Product Line

**Dimensional**

Width (in)	3.69
Length (in)	1.56
Height (in)	4.25
Size (Hex) or Size (Bolt)	3/8
Size (Hex) or Size (Bolt) - in	0.38
B Length (in)	2.75
Width (Fraction)	3-3/4
Height (Fraction) (in)	4-1/4

**General**

**Product Description**  
 Mechanical Grounding Connector,  
 Cable to Rod or Pipe, 4 AWG  
 (Sol)-2/0 AWG (Str), 2" Pipe,  
 2" -2-3/8" Rod, Bright Dipped

**Other**

Type of U Bolt 257

**Approvals / Certifications**

UL Listed	Y
CSA Certified	Y
ROHS Compatible	Exempt
UL Recognized	N
CULUS	N
Industry Standards	UL467
Rated for Direct Burial	Y

**Conductor(s)**

Copper Tube Size (SCH40) - Range	2 IPS IPS
Rod Size (Range)	2 in-2 3/8 in
Copper Solid Size (Range)	4 AWG-3/0 AWG
Copper Stranded (Range)	5 AWG-2/0 AWG
Rebar Size (Range)	N/A

**Physical**

Type of Hardware	DURIUM® Silicon Bronze
Installation Torque	240
Type of Plating	Bright Dipped
Plated (Yes or No)	N
Product Material	Copper Alloy

**Documentation**

For further technical assistance, please contact us

**BURNDY LLC - USA**

47 East Industrial Park Drive  
 Manchester NH 03109

**BURNDY Technical Services**

47 East Industrial Park Drive  
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM  
 Monday - Friday  
 Phone: 800-346-4175