

GROUND CLAMPS
Aluminum & Bronze
Ground Clamps
GCA & G SERIES



ALUMINUM GROUND CLAMPS



- Dual-rated ground clamp that grounds aluminum or copper to water pipe, galvanized pipe or steel conduit.
- Constructed from high-strength, extruded aluminum alloy and are plated to provide low-contact resistance.
- cULus Listed 467 Grounding and Bonding.
- Zinc plated steel screws.

All dimensional data is listed in inches.

CAT. NO.	PIPE SIZE (IPS)	GROUND WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
GCA-1	1/2-1	1/0-14 AWG	2.260	0.685	1.670	25
GCA-2	1 1/4-2	250 MCM-6 AWG	3.760	0.828	2.930	10
GCA-4	2 1/2-4	250 MCM-6 AWG	6.125	0.996	4.630	3

BRONZE GROUND CLAMP WITH WIRE ADAPTERS




- For connecting unarmored wire to water pipe for grounding.
- Special pressure bar grips cable to lessen chances of grounding conductor being pulled out.
- Assembled with zinc-plated steel screws.

G-20



G-66

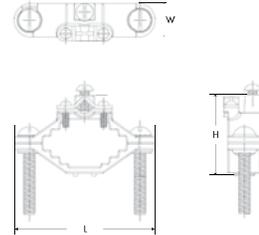

All dimensional data is listed in inches.

CAT. NO.	PIPE SIZE (IPS)	GROUND WIRE BOLT SIZE	GROUND CLAMP BOLT SIZE	GROUND WIRE RANGE	LENGTH (L)	WIDTH (W)	HEIGHT (H)	STD. CTN. QTY.
G-20	1/2-1	1/4 - 20 x 1/2	1/4 - 20 x 1 1/2	4,6,8 STR	2.250	1.000	1.350	20
G-66	1 1/4-2	1/4 - 20 x 1/2	5/16 - 18 x 2	4,6,8 STR	3.580	0.850	2.040	10