




BURNDY Catalog Number
UPC Number
Description
Status

GD1829
 7818102603333
 2/0-250 (2) CU 2.4 GRD
 Active

Web Use
 BURNDY Product Line

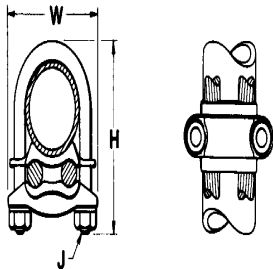

| Dimensional | |
|----------------------------------|---|
| Width (in) | 3.69 |
| Height (in) | 4.38 |
| Size (Hex) or Size (Bolt) | 3/8 |
| Size (Hex) or Size (Bolt) - in | 0.38 |
| Width (Fraction) | 3-3/4 |
| Height (Fraction) (in) | 4-3/8 |
| General | |
| Product Description | Mechanical Grounding Connector, 2 Parallel Cables to Rod or Pipe, 2/0 AWG (Sol.) - 250 kcmil, 2" to 2-3/8" Rod, 2" Pipe |
| Conductor(s) | |
| Copper Tube Size (SCH40) - Range | 2 |
| Rod Size (Range) | 2 in |
| Copper Solid Size (Range) | 2/0-4/0 |
| Copper Stranded (Range) | 2/0-250 |
| Physical | |
| Installation Torque | 240 |
| Type of Plating | Unplated |
| Plated (Yes or No) | N |
| Product Material | Copper Alloy |
| Approvals / Certifications | |
| UL Listed | Y |
| CSA Certified | N |
| ROHS Compatible | Exempt |
| UL Recognized | N |
| CULUS | N |
| Industry Standards | UL467 |
| Rated for Direct Burial | Y |
| Documentation | |

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175