

Straight Blade Devices 15A, 125V, 2 Pole, 3 Wire Grounding Insulgrip Plug

HUBBELL

Features

- 8-Position angled plug
- Low profile
- Roomy wiring chamber provides ample space for wiring

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
8-position angle plug, black and white nylon	.325"-.655"(8.3-16.6)	783585173054	HBL5266CA

Listings

UL Listed to UL498 File E1706
 CSA Certified to C22.2 No. 42 File 280
 Fed. Spec. W-C596G
 NEMA® WD-6 Compliant



Specifications

Housing/Cord Clamp	Nylon
Blade Holder	Nylon
Terminal Retainer	Clear Polycarbonate
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

Performance

Electrical	
Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum
Mechanical	
Cord Accomodation	.325"-.655"(8.3-16.6)
Terminal Accommodation	#18-10 AWG. Standed copper wire only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

Environmental	
Flammability	UL 94 HB or better
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

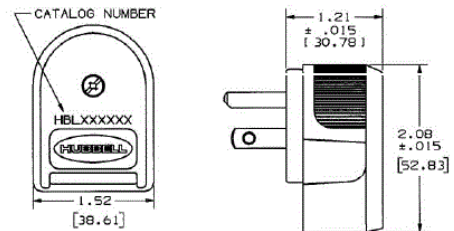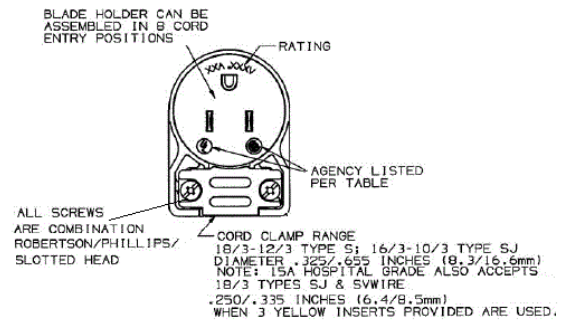

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

