

Twist-Lock® Devices Switched Enclosure Auxillary Contact Auxillary Contact


HUBBELL

Ordering Information

Description	Contact Type	UPC	Catalog Number
Auxiliary contact	Break after Break	783585955117	HBLAC1

Listings

Listed to UL Standard
Certified to CSA Standard
Type 3R and 12K Enclosure Rating

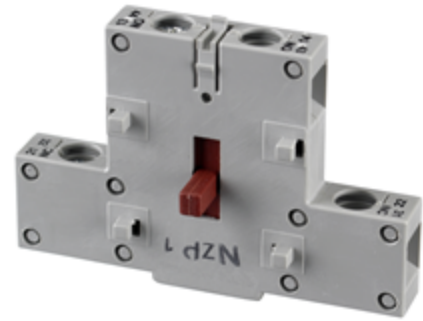

Performance

Electrical

Current Interrupting Certified for current interrupting at full rated current voltage

Dielectric Voltage Withstands 3,000V Min
Max. Working Voltage 600V RMS
Operations Mechanical 10,000 cycles; Electrical 6,000 cycles

Mechanical

Impact Resistance In accordance with UL 746C
Mounting External full adjustable feet
Product Identification Identification and ratings are part of the external label and receptacle face
Terminal Identification In accordance with UL, CSA

Environmental

Flammability Meets UL 94V0 material classification
Moisture Resistance IP66 suitability
Operating Temperature Maximum continuous +75°C; Minimum continuous -40°C
UV Resistance All exposed materials are UV stabilized

Accessories

Enclosure Accommodation Hubbell Non-Fused Switched Enclosures and Non-Fused Mechanical Interlocks with Gray Interior Switches

Resources

[eCatalog](#)

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

