



HALO HLS Disk Lights are wet location-listed, bright, energy-efficient surface mount fixtures that are fast and easy to install in residential downlighting applications like bathrooms, hallways, closets, and laundry rooms.

These low-profile fixtures include everything you need to install in standard/pancake junction boxes or recessed housings. Safe for wet locations like showers or covered outdoor areas and dimmable to 10%*.

Available in individual and contractor bulk packs in both selectable or dedicated color temperatures.

Product Features

- 4", 6", 9", and 9" with motion sensor* Disk Lights with low-profile lens and tapered trim
- Installs in most standard/pancake 30/40 (3-1/2"/4") junction boxes
- Ultra-fast mounting with twist-release lens and keyhole slots (no clips or plates needed)
- 5-color Field-SeleCCTable 27/30/35/40/5000K or Dedicated 3000K, 4000K, 5000K; 90+ CRI
- Dimming: Dims to 10% (phase cut LE/TE) with compatible dimmers; 120V input
- AIR-TITE, damp location rated, IC-rated, and ENERGY STAR® certified
- Decorative Overlays available in Paintable Matte White, Matte Black, Satin Nickel and Tuscan Bronze



Select the perfect color temperature for your space with 5 color temperatures between soft white (2700K) to daylight (5000K).



LEARN MORE

Decorative Overlay Finishes



Paintable Matte White



Matte Black



Satin Nickel




Tuscan Bronze



Junction Box Installation

1. Twist & remove lens
2. Wire fixture
3. Line up fixture keyholes to junction box to install

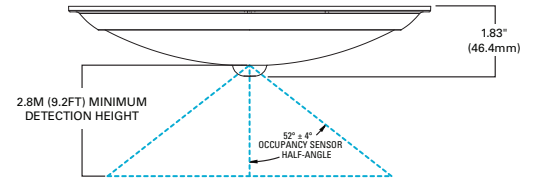

Motion Sensor Benefits

- Convenience / Safety - Lights come on as you enter
- Energy Cost savings - Automatically turns off to reduce energy usage
- Sleek design - Perfect for residential applications

*Damp location rated only - not available with dimming

Order Information

4" Disk Lights

Catalog Number	Description	CRI	CCT	Dimming	Finish	Packaging	Packaging Dimensions	UPC
HLS4079FS1E-6BP	4-inch LED Disk Light 800 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	6 Pack	7.283" x 7.48" x 7.874"	080083286980
HLS4079FS1E-12BP	4-inch LED Disk Light 800 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	12 Pack	7.283" x 7.48" x 15.748"	080083287000

6" Disk Lights

HLS6099FS1E-6BP	6-inch LED Disk Light 1200 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	6 Pack	8.858" x 7.677" x 8.858"	080083287024
HLS6099FS1E-12BP	6-inch LED Disk Light 1200 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	12 Pack	8.858" x 8.858" x 15.354"	080083287048

9" Disk Lights

HLS9129FS1E	6-inch LED Disk Light 1300 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	Single Pack		080083287062
HLS9129FS1E-CA	6-inch LED Disk Light 1300 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	Single Pack - California		080083287086
HLSMS9129FS1E	6-inch LED Disk Light with Motion Sensor 1300 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	Single Pack		080083287109
HLSMS9129FS1E-CA	6-inch LED Disk Light with Motion Sensor 1300 lumens	90+ CRI	5CCT (2700K, 3000K, 3500K, 4000K, 5000K)	Phase Cut dimming 10%	Matte White	Single Pack - California		080083287123

See spec sheets at halolighting.com for all fixture options.

2-in-1 installation


Junction Box Installation



1. Twist & remove lens
2. Wire fixture
3. Line up fixture keyholes to jbox to install



Housing Installation

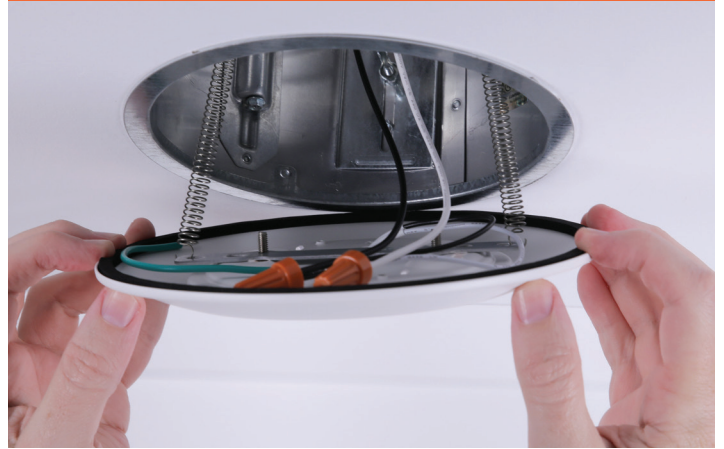

1. Twist & remove lens
2. Wire fixture to Edison adapter
3. Use springs (included) to attach fixture to the housing

