

BURNDY Catalog Number
UPC Number
Description
Status

KA34U
 7818103702477
 4STR-500 DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

| | |
|---------------------|------|
| Width (in) | 1.51 |
| Length (in) | 2.81 |
| Bolt Hole Size (in) | 0.38 |
| Thickness | 0.31 |
| D - in | 1.50 |
| Pad Width (in) | 1.52 |
| N (in) | 0.88 |

General

| | |
|----------------------|---|
| Number of Conductors | 1 |
| Number of Holes | 1 |
| Product Description | Aluminum Universal Terminal, 1 Hole, 4 AWG (Str)-500 kcmil, 3/8" Stud, 1 Screw, Al/Cu Rated, Tin Plated |

Conductor(s)

| | |
|---------------------------|------------------|
| Aluminum Size (Range) | 4 STR- 500 kcmil |
| Copper Solid Size (Range) | N/A |
| Copper Stranded (Range) | 4 AWG-500 kcmil |

Physical

| | |
|---------------------|----------|
| Installation Torque | 500 |
| Type of Plating | Tin |
| Connector Type | Terminal |
| Bolt Hole Size | 3/8 |
| Plated (Yes or No) | Y |
| Product Material | Aluminum |

Approvals / Certifications

| | |
|-------------------------|-------------|
| Rated for Direct Burial | N |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Exempt |
| Industry Standards | UL468A-468B |

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

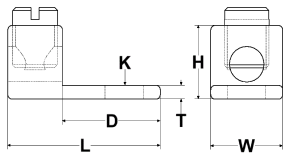

BURNDY Catalog Number
UPC Number
Description
Status

KA34U
 7818103702477
 4STR-500 DUAL RATED
 Active

Web Use
 BURNDY Product Line

Dimensional

| | |
|---------------------|------|
| Width (in) | 1.51 |
| Length (in) | 2.81 |
| Bolt Hole Size (in) | 0.38 |
| Thickness | 0.31 |
| D - in | 1.50 |
| Pad Width (in) | 1.52 |
| N (in) | 0.88 |

General

| | |
|----------------------|---|
| Number of Conductors | 1 |
| Number of Holes | 1 |
| Product Description | Aluminum Universal Terminal, 1 Hole, 4 AWG (Str)-500 kcmil, 3/8" Stud, 1 Screw, Al/Cu Rated, Tin Plated |

Conductor(s)

| | |
|---------------------------|------------------|
| Aluminum Size (Range) | 4 STR- 500 kcmil |
| Copper Solid Size (Range) | N/A |
| Copper Stranded (Range) | 4 AWG-500 kcmil |

Physical

| | |
|---------------------|----------|
| Installation Torque | 500 |
| Type of Plating | Tin |
| Connector Type | Terminal |
| Bolt Hole Size | 3/8 |
| Plated (Yes or No) | Y |
| Product Material | Aluminum |

Approvals / Certifications

| | |
|-------------------------|-------------|
| Rated for Direct Burial | N |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Exempt |
| Industry Standards | UL468A-468B |

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM

Monday - Friday

Phone: 800-346-4175