

BURNDY Catalog Number
UPC Number
Description
Status

KA4C
 7818103614055
 14-4 CU LUG ST SCR 1H
 Active

Web Use
 BURNDY Product Line

| Dimensional | |
|--------------------------------|---|
| Size (Hex) or Size (Bolt) | 5/16 |
| Length (in) | 1.11 |
| Thickness (in) | 1/10 |
| Height (in) | 0.77 |
| B Length (Fraction) | 8/17 |
| Hole Size (Fraction) | 9/32 |
| Stud Size (in) | 1/4 |
| Thickness | 0.10 |
| Size (Hex) or Size (Bolt) - in | 0.31 |
| B Length (in) | 0.47 |
| Pad Width (in) | 0.54 |
| N (Fraction) | 1/4 |
| N (in) | 0.25 |
| Hole Size (in) | 0.28 |
| Length (Fraction) | 1-1/8 |
| Height (Fraction) (in) | 3/4 |
| General | |
| Product Description | Copper Terminal, 1 Hole, 14 AWG (Sol)-4 AWG (Str), 1/4" Stud, 1 Screw |
| Conductor(s) | |
| Copper Solid Size (Range) | 14 AWG-4 AWG |
| Copper Stranded (Range) | 14 AWG-4 AWG |
| Physical | |
| Screw Type | Slot |
| Type of Hardware | 5 / 16 " |
| Installation Torque | 45 |
| Type of Plating | Unplated |
| Connector Type | Terminal |
| Plated (Yes or No) | N |
| Product Material | Copper |
| Approvals / Certifications | |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Compliant |
| UL Recognized | N |
| CULUS | N |
| Industry Standards | UL468A-468B |
| Documentation | |

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

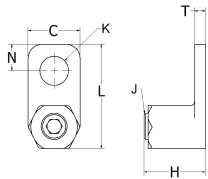

BURNDY Catalog Number
UPC Number
Description
Status

KA4C
 7818103614055
 14-4 CU LUG ST SCR 1H
 Active

Web Use
 BURNDY Product Line

| Dimensional | |
|--------------------------------|---|
| Size (Hex) or Size (Bolt) | 5/16 |
| Length (in) | 1.11 |
| Thickness (in) | 1/10 |
| Height (in) | 0.77 |
| B Length (Fraction) | 8/17 |
| Hole Size (Fraction) | 9/32 |
| Stud Size (in) | 1/4 |
| Thickness | 0.10 |
| Size (Hex) or Size (Bolt) - in | 0.31 |
| B Length (in) | 0.47 |
| Pad Width (in) | 0.54 |
| N (Fraction) | 1/4 |
| N (in) | 0.25 |
| Hole Size (in) | 0.28 |
| Length (Fraction) | 1-1/8 |
| Height (Fraction) (in) | 3/4 |
| General | |
| Product Description | Copper Terminal, 1 Hole, 14 AWG (Sol)-4 AWG (Str), 1/4" Stud, 1 Screw |
| Conductor(s) | |
| Copper Solid Size (Range) | 14 AWG-4 AWG |
| Copper Stranded (Range) | 14 AWG-4 AWG |
| Physical | |
| Screw Type | Slot |
| Type of Hardware | 5 / 16 " |
| Installation Torque | 45 |
| Type of Plating | Unplated |
| Connector Type | Terminal |
| Plated (Yes or No) | N |
| Product Material | Copper |
| Approvals / Certifications | |
| UL Listed | Y |
| CSA Certified | Y |
| ROHS Compatible | Compliant |
| UL Recognized | N |
| CULUS | N |
| Industry Standards | UL468A-468B |
| Documentation | |

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175