

BURNDY Catalog Number
UPC Number
Description
Status

KS20
 7818100120000
 SERVIT 8 STR - 4 SOL
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.51
 Size (Hex) or Size (Bolt) 1/2
 Cross Flats 0.69
 Size (Hex) or Size (Bolt) - in 0.500
 B Length (in) .65
 B Length (Fraction) 13/20

General

Product Description

Copper Split Bolt, Cu: 8 AWG
 (Str)-6 AWG (Sol) (Run &
 Tap),Length:1.20

Conductor(s)

Copper Tap Range 14 AWG-4 AWG
 CopperWeld Solid Run Size (Range) 8 AWG-4 AWG
 Copper Stranded Run (Range) 8 AWG-4 AWG
 CopperWeld Stranded Tap Size (Range) 3#10-8D
 Copper Solid Tap (Range) 14 AWG-4 AWG
 CopperWeld Solid Tap Size (Range) #4
 Copper Solid Run Size (Range) 8 AWG-4 AWG
 CopperWeld Stranded Run Size (Range) 3#10-8D

Physical

Installation Torque 165
 Type of Plating Unplated
 Connector Type Split Bolt
 Plated (Yes or No) N
 Product Material Copper

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards RUS

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

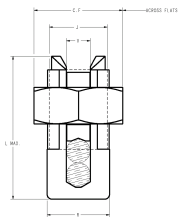

BURNDY Catalog Number
UPC Number
Description
Status

KS20
 7818100120000
 SERVIT 8 STR - 4 SOL
 Active

Web Use
 BURNDY Product Line

Dimensional

Width (in) 0.51
 Size (Hex) or Size (Bolt) 1/2
 Cross Flats 0.69
 Size (Hex) or Size (Bolt) - in 0.500
 B Length (in) .65
 B Length (Fraction) 13/20

General

Product Description

Copper Split Bolt, Cu: 8 AWG
 (Str)-6 AWG (Sol) (Run &
 Tap),Length:1.20

Conductor(s)

Copper Tap Range 14 AWG-4 AWG
 CopperWeld Solid Run Size (Range) 8 AWG-4 AWG
 Copper Stranded Run (Range) 8 AWG-4 AWG
 CopperWeld Stranded Tap Size (Range) 3#10-8D
 Copper Solid Tap (Range) 14 AWG-4 AWG
 CopperWeld Solid Tap Size (Range) #4
 Copper Solid Run Size (Range) 8 AWG-4 AWG
 CopperWeld Stranded Run Size (Range) 3#10-8D

Physical

Installation Torque 165
 Type of Plating Unplated
 Connector Type Split Bolt
 Plated (Yes or No) N
 Product Material Copper

Approvals / Certifications

Rated for Direct Burial Y
 UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards RUS

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175