

Commercial Specification Grade Locking Devices

3 Pole, 4 Wire Grounding
 NEMA L14-20, 20A 125/250V
 NEMA L15-20, 20A 250V 3Ø
 NEMA L16-20, 20A 480V 3Ø



INDUSTRIAL
 COMMERCIAL
 RESIDENTIAL

E-38 LOCKING DEVICES

TESTING & CODE COMPLIANCE

- Listed to UL 498 Receptacles: (file no. E15058). UL verified to Federal Spec. WC-596; Plugs & Connectors: (file no. E15012).
- Certified to CSA C22.2 no.42. Receptacles: (file no. LR6914 (6233-01)). Plugs & Connectors: (file no. LR2081 (6221-02)).
- NOM Certified, except as noted.


MATERIAL CHARACTERISTICS

- Receptacles: Nylon.
- Plugs, Connectors: Polycarbonate & PVC. Meets flammability requirements per UL 94, V2 rated.
- Temperature Rating: Receptacles: -40°C to 70°C Plugs & Connectors: -20°C to 60°C.

20A 3 Pole, 4 Wire Commercial Specification Grade Receptacles

FEATURES

- Rugged nylon face and body.
- Clearly marked rating, NEMA configuration and approval listings on receptacle face.
- One piece brass contacts offer superior performance and minimum heat rise.
- Back wire terminal clamps for easy secure wiring.
- Combination head screws standard - slot/Phillips in the U.S.

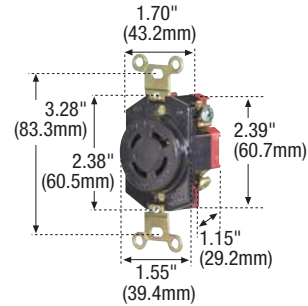

L1620R

Commercial Specification Grade Receptacles

Rating	A	V/AC	NEMA	Description	Color	Catalog No.
20		125/250	L14-20	Single	Black	L1420R
20		250V 3Ø	L15-20	Single	Black	L1520R
20		480V 3Ø	L16-20	Single	Black	L1620R*

*Not CSA or NOM

20A 3 Pole, 4 Wire Commercial Specification Grade Locking Plugs and Connectors

FEATURES

- Abuse resistant thermoplastic construction.
- Back wire Dead-Front design.
- External cable clamp provides firm strain relief.
- Back wire terminal clamps for easy secure wiring.
- Individual wiring compartments with tapered channel for easy insertion of wires.
- Triple combination head screws standard - slot/Phillips/Robertson for use in the U.S. and Canada.
- Clear cover over wiring compartments allow easy inspection of wiring terminations.
- Clearly marked rating, NEMA configuration and standard compliances on face of plug or connector.



L1420P



L1420C



L1520C

Commercial Specification Grade Locking Plugs and Connectors

Rating	A	V/AC	NEMA	Description/ Cord Diameter	Color	Plug	Connector
20		125/250	L14-20	Straight: 0.25"-0.69" (6.35mm-17.5mm)	Black & White	L1420P	L1420C
20		250V 3Ø	L15-20	Straight: 0.25"-0.69" (6.35mm-17.5mm)	Black & White	L1520P	L1520C

NOTE: Weather Protective Covers and Boots from Cooper Wiring Devices that may be used with these products are described on pages E-71 and E-72 in this section.



L14-20P

L14-20R

L15-20P

L15-20R

L16-20R