



# ESSENTIAL SERIES

GENERAL PURPOSE LED BULBS

## KT-LED5.5FG25-E26-9XX-F

REPLACEMENT LAMP

### DESCRIPTION

5.5W G25 Lamp | 2700–5000K |  $\geq 90$  CRI | Frosted Globe



**LAMP TYPE:** Filament G25

**BASE TYPE:** E26 (Medium)

**WATTAGE:** 5.5W

**COLOR TEMPERATURE:** 2700–5000K

**COLOR RENDERING INDEX (CRI):**  $\geq 90$

**WARRANTY:** 3 Years

**RATED LIFE:** L70 (15,000 Hours)



### TYPICAL APPLICATIONS

- Chandeliers
- Vanity Fixtures
- Decorative Accent Lighting
- Wall Sconces
- Pendant Lights

### PRODUCT FEATURES

- Energy efficient, 80%+ energy savings over legacy equivalents
- Lower heat generation than legacy equivalents
- Smooth, uniform dimming
- Filament-style LED construction offers unique traditional appearance for decorative and mood-sensitive applications
- HiCRI LEDs offer enhanced color rendering vs. 80 CRI LEDs, providing ideal clarity, representation, uniformity of illuminated area/objects
- Long life minimizes replacement and maintenance costs
- Suitable for use in damp locations
- Operating temperature range  $-4^{\circ}\text{F}/-20^{\circ}\text{C}$  to  $95^{\circ}\text{F}/35^{\circ}\text{C}$
- PF  $> 0.70$
- Rated for open, recessed, and enclosed fixtures
- ANSI compliant construction ensures fitment for intended applications
- UL Listed
- Meets Energy Star requirements
- Complies with Part 15 of FCC
- Title 20 compliant

### ELECTRICAL AND PERFORMANCE SPECIFICATIONS


Keystone Catalog Number	Description	Color Temp*	Input Voltage	Rated Lamp Wattage	Legacy Equivalent Wattage	Lumens	Efficacy	CRI	Base Type	Beam Angle	Dimmable
KT-LED5.5FG25-E26-927-F	G25 filament globe bulb; Frosted; Dimmable	2700K	120V	5.5W	60W incandescent	500 lm	91 lm/W	$\geq 90$	E26	360°	Yes
KT-LED5.5FG25-E26-930-F	G25 filament globe bulb; Frosted; Dimmable	3000K	120V	5.5W	60W incandescent	500 lm	91 lm/W	$\geq 90$	E26	360°	Yes
KT-LED5.5FG25-E26-950-F	G25 filament globe bulb; Frosted; Dimmable	5000K	120V	5.5W	60W incandescent	500 lm	91 lm/W	$\geq 90$	E26	360°	Yes

\* Color Uniformity: CCT (Correlated Color Temperature) range as per guidelines outlined in ANSI C78.377-2017

## KT-LED5.5FG25-E26-9XX-F

### REPLACEMENT LAMP

#### PHYSICAL CHARACTERISTICS

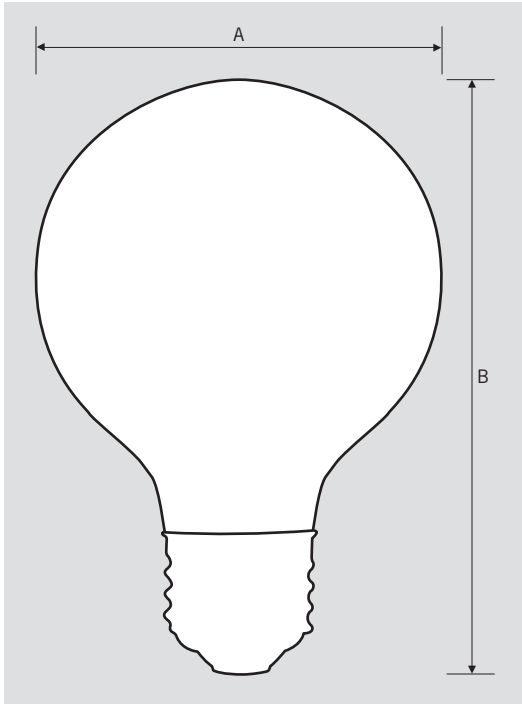

#### LAMP DIMENSIONS

A (Diameter)	3.15"
B (Length)	4.53"

BASE TYPE: E26 (Medium)

#### RATED LIFE

L70 (Hours)	15,000
-------------	--------

#### PACKAGING

Carton Quantity	24 pcs
Carton Dimensions	15.54" × 11.42" × 11.82"
Carton Weight	5.52 lbs

#### ORDERING INFORMATION

ORDER CODE	CARTON QUANTITY	ITEM STATUS	EASY CODE	UPC
KT-LED5.5FG25-E26-927-F	24 pcs	Active	UGF-75	843654123820
KT-LED5.5FG25-E26-930-F	24 pcs	Active	FNE-30	843654129600
KT-LED5.5FG25-E26-950-F	24 pcs	Active	RKH-43	843654123837

#### CATALOG NUMBER BREAKDOWN

## KT-LED5.5FG25-E26-9XX-F

1 2 3 4 5 6 7 8 9

- 1 Keystone Technologies
- 2 LED Lamp
- 3 Wattage
- 4 Filament Bulb
- 5 Lamp Shape
- 6 Base Type
- 7 900 Series
- 8 Color Temperature
- 9 Frosted Bulb