




GE
Lighting

68161 - LED10DR303V/830W

GE LED Floodlight

• Energy-efficient LED lamps. Long life.

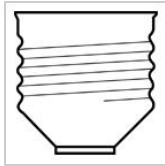

GENERAL CHARACTERISTICS

Lamp Type	Replacement Lamps - Directional
Bulb	BR30
Base	Medium Screw (E26)
Additional Info	Frosted, white, BR30
Bulb Shape	BR30
Color	White
Dimming Capability	Operates on dimming circuits. See GELighting.com/dimming for further information
Equivalent Wattage (NOM)	65.0 W
Lamp Type	LED-BR
Life in Years (NOM)	22.8
Rated Life (MIN)	25000.0 h
Rated Life (NOM)	25000.0 h

PHOTOMETRIC CHARACTERISTICS

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	3000.0 K
Initial Lumens (NOM)	700.0
Lumens per Watt (Efficacy) (NOM)	70.0 lm
Nominal Initial Lumens per Watt (NOM)	70.0

ELECTRICAL CHARACTERISTICS

Estimated Energy Cost per Year (NOM)	1.2
Voltage (NOM)	120.0
Wattage (NOM)	10.0

DIMENSIONS

Bulb Diameter (DIA) (NOM)	3.750 in(95.2 mm)
Maximum Overall Length (MOL) (NOM)	5.370 in(136.4 mm)

PRODUCT INFORMATION

Product Code	68161
Description	LED10DR303V/830W
Standard Package	00-Case
Standard Package GTIN	10043168681619
Standard Package Quantity	6
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168681612




GE
Lighting

68161 - LED10DR303V/830W

GE LED Floodlight

• Energy-efficient LED lamps. Long life.

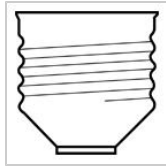

GENERAL CHARACTERISTICS

Lamp Type	Replacement Lamps - Directional
Bulb	BR30
Base	Medium Screw (E26)
Additional Info	Frosted, white, BR30
Bulb Shape	BR30
Color	White
Dimming Capability	Operates on dimming circuits. See GELighting.com/dimming for further information
Equivalent Wattage (NOM)	65.0 W
Lamp Type	LED-BR
Life in Years (NOM)	22.8
Rated Life (MIN)	25000.0 h
Rated Life (NOM)	25000.0 h

PHOTOMETRIC CHARACTERISTICS

Color Rendering Index (CRI) (NOM)	80.0
Color Temperature (NOM)	3000.0 K
Initial Lumens (NOM)	700.0
Lumens per Watt (Efficacy) (NOM)	70.0 lm
Nominal Initial Lumens per Watt (NOM)	70.0

ELECTRICAL CHARACTERISTICS

Estimated Energy Cost per Year (NOM)	1.2
Voltage (NOM)	120.0
Wattage (NOM)	10.0

DIMENSIONS

Bulb Diameter (DIA) (NOM)	3.750 in(95.2 mm)
Maximum Overall Length (MOL) (NOM)	5.370 in(136.4 mm)

PRODUCT INFORMATION

Product Code	68161
Description	LED10DR303V/830W
Standard Package	00-Case
Standard Package GTIN	10043168681619
Standard Package Quantity	6
Sales Unit	Layer
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168681612