

F7 F8 M9 Conduit Bodies

Catalog Number: LR37
 UPC: 736953010178



Description

1 Inch Form 7 LR Conduit Body

PVC coated Form 7 conduit bodies with covers are offered in numerous configurations to provide a complete coated conduit system. Electrical continuity of the conduit system is maintained across assembled joints.

Application

- Offered in numerous configurations for 90 degree bends, taps or splices or mounting outlets
- Offered in numerous configurations for 90 degree bends, taps or splices or mounting outlets

Features

- 10 trade sizes from 1/2" through 4"
- 2 mil green urethane interior coating
- 40 mil gray PVC exterior coating
- Cover uses retained stainless screw and wedge clip design
- Sealing sleeves on all conduit openings

General



Body Style:	LR
Exterior Finish:	A nominal .040 inch (40 mil) gray PVC coating
Interior Finish:	A nominal .002 inch (2 mil) green urethane
Material:	FERROUS METAL
Screw Type:	Self-retaining stainless steel cover screws

Dimensions

Dimension A (Inches)	6.04
Dimension B (Inches)	1.92
Dimension C (Inches)	2.79
Dimension D (Inches)	1.38
Dimension E (Inches)	4.5
Nominal Weight (Pounds)	2.1

Technical / Specification Documents

Specification Guide (1995 Master)	AVAILABLE ON WEBSITE
Specification Guide (2004 Master)	AVAILABLE ON WEBSITE
Installer Certification and Tools	AVAILABLE ON WEBSITE
Chemical Resistance Charts	AVAILABLE ON WEBSITE
Performance Specifications	AVAILABLE ON WEBSITE

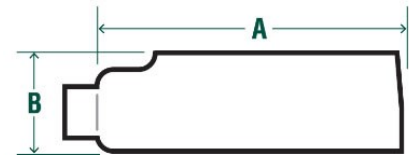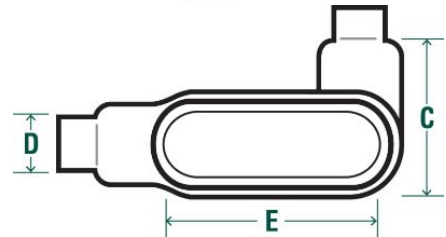

F7 F8 M9 Conduit Bodies

Catalog Number: LR37

UPC: 736953010178



Standards

UL 514A, 514D: E231035

CSA Certified: C22.2 No.18

CSA Certified: C22.2 No. 42

Notes

Not available with encapsulated screws.

All cover screws are stainless steel

F7 F8 M9 Conduit Bodies

Catalog Number: LR37
 UPC: 736953010178



Description

1 Inch Form 7 LR Conduit Body

PVC coated Form 7 conduit bodies with covers are offered in numerous configurations to provide a complete coated conduit system. Electrical continuity of the conduit system is maintained across assembled joints.

Application

- Offered in numerous configurations for 90 degree bends, taps or splices or mounting outlets
- Offered in numerous configurations for 90 degree bends, taps or splices or mounting outlets

Features

- 10 trade sizes from 1/2" through 4"
- 2 mil green urethane interior coating
- 40 mil gray PVC exterior coating
- Cover uses retained stainless screw and wedge clip design
- Sealing sleeves on all conduit openings

General



Body Style:	LR
Exterior Finish:	A nominal .040 inch (40 mil) gray PVC coating
Interior Finish:	A nominal .002 inch (2 mil) green urethane
Material:	FERROUS METAL
Screw Type:	Self-retaining stainless steel cover screws

Dimensions

Dimension A (Inches)	6.04
Dimension B (Inches)	1.92
Dimension C (Inches)	2.79
Dimension D (Inches)	1.38
Dimension E (Inches)	4.5
Nominal Weight (Pounds)	2.1

Technical / Specification Documents

Specification Guide (1995 Master)	AVAILABLE ON WEBSITE
Specification Guide (2004 Master)	AVAILABLE ON WEBSITE
Installer Certification and Tools	AVAILABLE ON WEBSITE
Chemical Resistance Charts	AVAILABLE ON WEBSITE
Performance Specifications	AVAILABLE ON WEBSITE

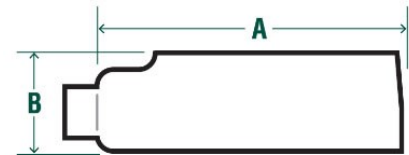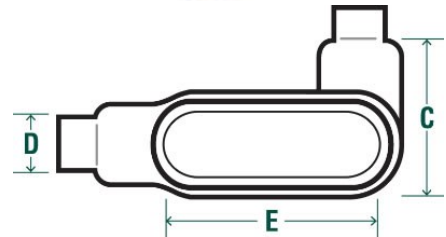

F7 F8 M9 Conduit Bodies

Catalog Number: LR37

UPC: 736953010178



Standards

UL 514A, 514D: E231035

CSA Certified: C22.2 No.18

CSA Certified: C22.2 No. 42

Notes

Not available with encapsulated screws.

All cover screws are stainless steel
