

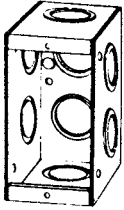
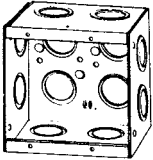
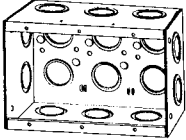
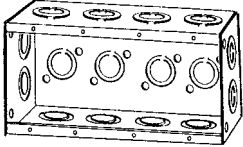

# Outlet and Switch Boxes

## Masonry Boxes

2-1/2" Deep x 3-3/4" High With Concentric Knockouts (Non-Gangable)

NEC:

Listed for Ordinary Locations

 
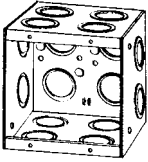
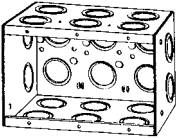
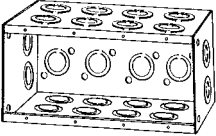

|                                                                                                                                        | Width<br>(Inches) | Wiring Cubic<br>Inch Capacity | Concentric Knockout Description        |                 |                 | Weight per 100<br>kg (lb) | Catalog Number |
|----------------------------------------------------------------------------------------------------------------------------------------|-------------------|-------------------------------|----------------------------------------|-----------------|-----------------|---------------------------|----------------|
|                                                                                                                                        |                   |                               | Sides                                  | Ends            | Bottom          |                           |                |
|  <p><b>1-13/16" Wide, Welded,<br/>Single gang</b></p> | 1-13/16           | 15.5                          | (4) 1/2" -<br>3/4"                     | (2) 1/2" - 3/4" | (2) 1/2" - 3/4" | 29.94<br>(66.0)           | M1-250         |
|  <p><b>3-5/8" Wide, Welded,<br/>Two gang</b></p>      | 3-5/8             | 31.0                          | (4) 1/2" -<br>3/4"                     | (4) 1/2" - 3/4" | (4) 1/2" - 3/4" | 52.62<br>(116.0)          | M2-250         |
|  <p><b>5-7/16" Wide, Welded;<br/>Three gang</b></p> | 5-7/16            | 46.5                          | (4) 1/2" -<br>3/4"                     | (6) 1/2" - 3/4" | (6) 1/2" - 3/4" | 63.50<br>(140.0)          | M3-250         |
|  <p><b>7-3/8" Wide, Welded,<br/>Four gang</b></p>   | 7-3/8             | 67.0                          | (4) 1/2" -<br>3/4"                     | (8) 1/2" - 3/4" | (4) 1/2" - 3/4" | 72.57<br>(160.0)          | M4-250         |
| <b>Low Voltage Partitions</b>                                                                                                          |                   |                               |                                        |                 |                 |                           |                |
|                                                     |                   | 0.0                           | For 2-1/2" 2- and 3-Gang Masonry Boxes |                 |                 | 7.26<br>(16.0)            | LVP-250        |

# Outlet and Switch Boxes

## Masonry Boxes

3-1/2" Deep x 3-3/4" High with Concentric Knockouts (Non-Gangable)

NEC:  
Listed for Ordinary Locations

|                                                                                                                            | Depth (Inches) | Wiring Cubic Inch Capacity | Knockout Description                       |                  |                 | Weight per 100 kg (lb) | Catalog Number |
|----------------------------------------------------------------------------------------------------------------------------|----------------|----------------------------|--------------------------------------------|------------------|-----------------|------------------------|----------------|
|                                                                                                                            |                |                            | Sides                                      | Ends             | Bottom          |                        |                |
|  <p>1-13/16" Wide, Welded Single gang</p> | 1-13/16        | 22.0                       | (4) 1/2" - 3/4"                            | (4) 1/2" - 3/4"  | (2) 1/2" - 3/4" | 39.01 (86.0)           | M1-350         |
|  <p>3-5/8" Wide, Welded Two gang</p>      | 3-5/8          | 44.0                       | (4) 1/2" - 3/4"                            | (8) 1/2" - 3/4"  | (4) 1/2" - 3/4" | 57.15 (126.0)          | M2-350         |
|  <p>5-7/16" Wide, Welded Three gang</p> | 5-7/16         | 66.0                       | (4) 1/2" - 3/4"                            | (12) 1/2" - 3/4" | (6) 1/2" - 3/4" | 73.94 (163.0)          | M3-350         |
|  <p>7-3/8" Wide, Welded Four gang</p>   | 7-3/8          | 92.0                       | (4) 1/2" - 3/4"                            | (16) 1/2" - 3/4" | (4) 1/2" - 3/4" | 90.72 (200.0)          | M4-350         |
| <p>Low Voltage Partitions</p>           |                | 0.0                        | For 3-1/2" 2-, 3- and 4-Gang Masonry Boxes |                  |                 | 10.89 (24.0)           | LVP-350        |

Appleton OZGEDNEY

COMMERCIAL AND INDUSTRIAL FITTINGS: OUTLET BOXES, SWITCH BOXES AND COVERS

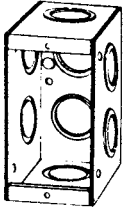
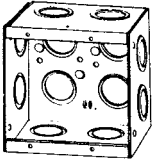
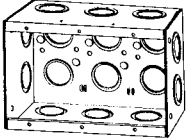
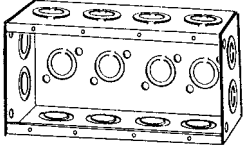

# Outlet and Switch Boxes

## Masonry Boxes

2-1/2" Deep x 3-3/4" High With Concentric Knockouts (Non-Gangable)

NEC:

Listed for Ordinary Locations

 
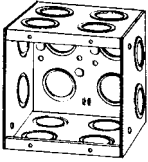
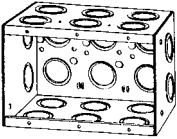
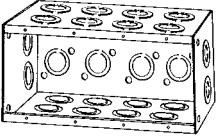

|                                                                                                                                        | Width<br>(Inches) | Wiring Cubic<br>Inch Capacity | Concentric Knockout Description        |                 |                 | Weight per 100<br>kg (lb) | Catalog Number |
|----------------------------------------------------------------------------------------------------------------------------------------|-------------------|-------------------------------|----------------------------------------|-----------------|-----------------|---------------------------|----------------|
|                                                                                                                                        |                   |                               | Sides                                  | Ends            | Bottom          |                           |                |
|  <p><b>1-13/16" Wide, Welded,<br/>Single gang</b></p> | 1-13/16           | 15.5                          | (4) 1/2" -<br>3/4"                     | (2) 1/2" - 3/4" | (2) 1/2" - 3/4" | 29.94<br>(66.0)           | M1-250         |
|  <p><b>3-5/8" Wide, Welded,<br/>Two gang</b></p>      | 3-5/8             | 31.0                          | (4) 1/2" -<br>3/4"                     | (4) 1/2" - 3/4" | (4) 1/2" - 3/4" | 52.62<br>(116.0)          | M2-250         |
|  <p><b>5-7/16" Wide, Welded;<br/>Three gang</b></p> | 5-7/16            | 46.5                          | (4) 1/2" -<br>3/4"                     | (6) 1/2" - 3/4" | (6) 1/2" - 3/4" | 63.50<br>(140.0)          | M3-250         |
|  <p><b>7-3/8" Wide, Welded,<br/>Four gang</b></p>   | 7-3/8             | 67.0                          | (4) 1/2" -<br>3/4"                     | (8) 1/2" - 3/4" | (4) 1/2" - 3/4" | 72.57<br>(160.0)          | M4-250         |
| <b>Low Voltage Partitions</b>                                                                                                          |                   |                               |                                        |                 |                 |                           |                |
|                                                     |                   | 0.0                           | For 2-1/2" 2- and 3-Gang Masonry Boxes |                 |                 | 7.26<br>(16.0)            | LVP-250        |

# Outlet and Switch Boxes

## Masonry Boxes

3-1/2" Deep x 3-3/4" High with Concentric Knockouts (Non-Gangable)

NEC:  
Listed for Ordinary Locations

|                                                                                                                                   | Depth<br>(Inches) | Wiring Cubic<br>Inch Capacity | Knockout Description                       |                  |                    | Weight per 100<br>kg (lb) | Catalog Number |
|-----------------------------------------------------------------------------------------------------------------------------------|-------------------|-------------------------------|--------------------------------------------|------------------|--------------------|---------------------------|----------------|
|                                                                                                                                   |                   |                               | Sides                                      | Ends             | Bottom             |                           |                |
| <br><b>1-13/16" Wide, Welded<br/>Single gang</b> | 1-13/16           | 22.0                          | (4) 1/2" -<br>3/4"                         | (4) 1/2" - 3/4"  | (2) 1/2" -<br>3/4" | 39.01<br>(86.0)           | <b>M1-350</b>  |
| <br><b>3-5/8" Wide, Welded<br/>Two gang</b>      | 3-5/8             | 44.0                          | (4) 1/2" -<br>3/4"                         | (8) 1/2" - 3/4"  | (4) 1/2" -<br>3/4" | 57.15<br>(126.0)          | <b>M2-350</b>  |
| <br><b>5-7/16" Wide, Welded<br/>Three gang</b> | 5-7/16            | 66.0                          | (4) 1/2" -<br>3/4"                         | (12) 1/2" - 3/4" | (6) 1/2" -<br>3/4" | 73.94<br>(163.0)          | <b>M3-350</b>  |
| <br><b>7-3/8" Wide, Welded<br/>Four gang</b>   | 7-3/8             | 92.0                          | (4) 1/2" -<br>3/4"                         | (16) 1/2" - 3/4" | (4) 1/2" -<br>3/4" | 90.72<br>(200.0)          | <b>M4-350</b>  |
| <b>Low Voltage Partitions</b>                                                                                                     |                   |                               |                                            |                  |                    |                           |                |
|                                                |                   | 0.0                           | For 3-1/2" 2-, 3- and 4-Gang Masonry Boxes |                  |                    | 10.89<br>(24.0)           | <b>LVP-350</b> |

Appleton OZGEDNEY

COMMERCIAL AND INDUSTRIAL FITTINGS: OUTLET BOXES, SWITCH BOXES AND COVERS