



## MC/AC CABLE SUPPORT BRACKET, 14-3 TO 10-2 MC/AC, 4 CABLE

### CATALOG NUMBER

**MCS50**



### CERTIFICATIONS



### FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation

### PRODUCT ATTRIBUTES

MC/AC Cable Size: 14-3 to 10-2

Super Neutral Cable Size: 10-2

Material: Steel

Finish: Electrogalvanized

Cable Capacity: 4

Hole Size 1 (HS1): 1/4"

Hole Size 2 (HS2): 0.2"

Outer Diameter (OD): 0.430" - 0.56"


## ADDITIONAL PRODUCT DETAILS

---

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

## DIAGRAMS

---

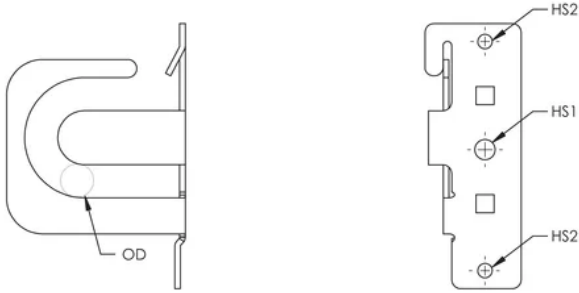

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**



## MC/AC CABLE SUPPORT BRACKET, 14-3 TO 10-2 MC/AC, 4 CABLE

### CATALOG NUMBER

**MCS50**



### CERTIFICATIONS



### FEATURES

Neatly isolates, supports and secures MC/AC cables

Properly spaces MC/AC cable to help eliminate bundling and NEC® & CEC derating issues

Results in a "neat and workmanlike" installation

### PRODUCT ATTRIBUTES

MC/AC Cable Size: 14-3 to 10-2

Super Neutral Cable Size: 10-2

Material: Steel

Finish: Electrogalvanized

Cable Capacity: 4

Hole Size 1 (HS1): 1/4"

Hole Size 2 (HS2): 0.2"

Outer Diameter (OD): 0.430" - 0.56"


## ADDITIONAL PRODUCT DETAILS

---

4Z parts installed on 3/8" (M10) smooth rod in the F2 direction has a Static Load Rating of 15 lb (67 N).

## DIAGRAMS

---

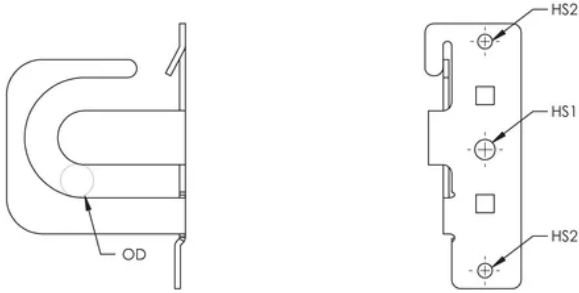

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical Support

### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:  
**nVent.com** **CADDY ERICO HOFFMAN RAYCHEM SCHROFF**  
**TRACER**