

# NMLT90150

## 90 Degree Non-Metallic Connectors



90 Degree Non-Metallic Connector

Country of Origin: USA

Weight: 0.410 lbs/each

Height: 4.470"

Width: 4.510"

Material(s): UV-Rated Plastic

Conduit Type: Non-Metallic Liquid Tight Conduit, Type B Only

Knockout Size(s): 1-1/2"

Trade Size: 1-1/2"

### Packaging

Unit: 2 pcs

Standard: 10 pcs




**Arlington**<sup>®</sup>

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
[www.aifittings.com](http://www.aifittings.com)

# NMLT90150

## 90 Degree Non-Metallic Connectors

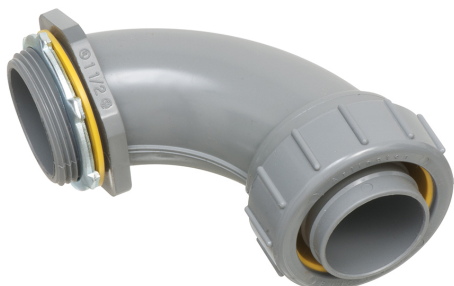

90 Degree Non-Metallic Connector

Country of Origin: USA

Weight: 0.410 lbs/each

Height: 4.470"

Width: 4.510"

Material(s): UV-Rated Plastic

Conduit Type: Non-Metallic Liquid Tight Conduit, Type B Only

Knockout Size(s): 1-1/2"

Trade Size: 1-1/2"

### Packaging

Unit: 2 pcs

Standard: 10 pcs



**Arlington**<sup>®</sup>

1 Stauffer Industrial Park  
Scranton, PA 18517  
800/233.4717  
Fax 570/562.0646  
[www.aifittings.com](http://www.aifittings.com)