




# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.  
75964-0000, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

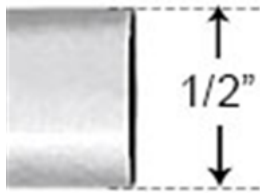

## PVC12 SCH 40 1/2" 10' PVC Conduit

*Heritage Plastics*

|                  |   |
|------------------|---|
| Catalog Number   | PVC12   |
| Manufacturer     | Heritage Plastics   |
| Description      | PVC Conduit, Underground or Aboveground Application, Gray Color, 0.578 In Conduit Inner Diameter, 0.840 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 6000 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 1/2 In Trade Size, 0.109 In Wall Thickness, 0.162 LB Weight |
| Weight per unit  | 0.1620 (lbs/each)   |
| Product Category | PVC Conduit, Fittings, & Boxes  |

### Dimensions and Weight

|          |      |
|----------|------|
| Diameter | 1/2" |
| Size     | 1/2  |

### Descriptions

|             |                             |
|-------------|-----------------------------|
| Description | SCH 40 1/2" 10' PVC CONDUIT |
|-------------|-----------------------------|

### Taxonomies, Classifications, and Categories

|                      |  |
|----------------------|--|
| Category Description | Conduit & Raceways - Pvc Conduit, Fittings, & Boxes<br>PVC Schedule 40 Conduit |
|----------------------|--|

### Availability

|             |    |
|-------------|----|
| minimum qty | 10 |
|-------------|----|

### Packaging

|                 |       |
|-----------------|-------|
| Carton          | 100   |
| Package         | 6000  |
| Weight Per foot | 0.162 |