




ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685

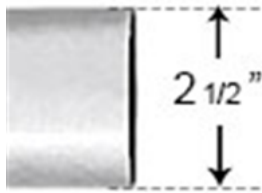

PVC212 SCH 40 2-1/2" 10' PVC Conduit

Heritage Plastics

Catalog Number	PVC212
Manufacturer	Heritage Plastics
Description	PVC Conduit, Underground or Aboveground Application, Gray Color, 2.414 In Conduit Inner Diameter, 2.875 In Conduit Outer Diameter, 10 FT Length, Made In Usa, +90 °C Maximum Operating Temperature, 930 FT/PK Package Quantity, Belled End;Corrosion Resistant;Rust Resistant;Sunlight Resistant;Rated For 90° Cable;Rigid Nonmetallic PVC Schedule 40 Special Features, Intertex Etl Listed Us;UI 651 and Nema TC2 Standards Met, 2-1/2 In Trade Size, 0.203 In Wall Thickness, 1.108 LB Weight
Weight per unit	1.1 (lbs/each)
Product Category	PVC Conduit, Fittings, & Boxes

Dimensions and Weight

Diameter	2-1/2"
----------	--------

Descriptions

Description	SCH 40 2-1/2" 10' PVC CONDUIT
-------------	-------------------------------

Manufacturer Information

Manufacturers Part Number	A52CE12
---------------------------	---------

Taxonomies, Classifications, and Categories

Category Description	PVC Schedule 40 Conduit
	Conduit & Raceways - Pvc Conduit, Fittings, & Boxes

Availability

minimum qty	10
-------------	----

Packaging

Carton	10
Package	930
Weight Per foot	1.108