




GE  
Lighting

## 23830 - Q1500T3/CL

GE halogen 1500 watt T3 1-pack

- 240 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts 1.8 years based on 3 hours per day usage
- T3 shape with Recessed Single Contact (R7s) base for use in outdoor carriage and post lights

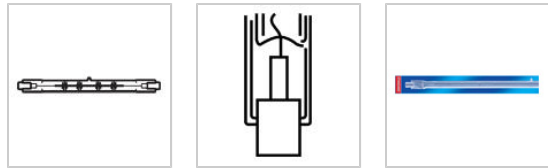

### GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Rated Life	2000.0 hrs

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	32000.0
Color Temperature	3050.0 K
Nominal Initial Lumens per Watt	21

### ELECTRICAL CHARACTERISTICS

Wattage	1500.0
Voltage	240.0
Burn Position	Horizontal

### DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.313 in(160.4 mm)

### PRODUCT INFORMATION

Product Code	23830
Description	Q1500T3/CL
Standard Package	Case
Standard Package GTIN	10043168238301
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168238304

### CAUTIONS & WARNINGS

#### Caution

- Lamp may shatter and cause injury if broken
  - Dispose of lamp in a closed container.
  - Do not use lamp if outer glass is scratched or broken.

#### Warning

- Lamp emits UV radiation which may cause eye/skin injury. RG-3
  - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Risk of Burn
  - Allow lamp to cool before handling.
  - Turn power off before installing lamp.
- Risk of Fire
  - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
  - Keep combustible materials away from lamp.
  - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not exceed 110% of rated voltage.
  - Do not touch glass with bare hands.
  - Do not use lamp if outer glass is scratched or broken.
  - Operate lamp only in specified position -- see instructions.
  - Use eye protection when handling lamp.
  - Use in enclosed fixture rated for this product.



GE  
Lighting

## 23830 - Q1500T3/CL

GE halogen 1500 watt T3 1-pack

- 240 volts
- GE halogen bulbs deliver crisp, white light. This unsurpassed light quality is ideal for adding depth, drama and interest to any room or space. Use GE halogen specialty bulbs to create a dramatic effect
- Lasts 1.8 years based on 3 hours per day usage
- T3 shape with Recessed Single Contact (R7s) base for use in outdoor carriage and post lights



### GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Rated Life	2000.0 hrs

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	32000.0
Color Temperature	3050.0 K
Nominal Initial Lumens per Watt	21

### ELECTRICAL CHARACTERISTICS


Wattage	1500.0
Voltage	240.0
Burn Position	Horizontal

### DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.313 in(160.4 mm)

### PRODUCT INFORMATION

Product Code	23830
Description	Q1500T3/CL
Standard Package	Case
Standard Package GTIN	10043168238301
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168238304

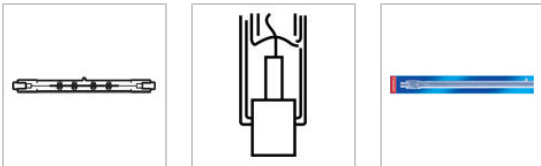

### CAUTIONS & WARNINGS

#### Caution

- Lamp may shatter and cause injury if broken
  - Dispose of lamp in a closed container.
  - Do not use lamp if outer glass is scratched or broken.

#### Warning

- Lamp emits UV radiation which may cause eye/skin injury. RG-3
  - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Risk of Burn
  - Allow lamp to cool before handling.
  - Turn power off before installing lamp.
- Risk of Fire
  - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
  - Keep combustible materials away from lamp.
  - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not exceed 110% of rated voltage.
  - Do not touch glass with bare hands.
  - Do not use lamp if outer glass is scratched or broken.
  - Operate lamp only in specified position -- see instructions.
  - Use eye protection when handling lamp.
  - Use in enclosed fixture rated for this product.