


# Eaton TP217

Catalog Number: TP217

Eaton Crouse-Hinds series Switch Box, (1) 1/2", Conduit (no clamps), 2-1/2", (1) 1/2", Steel, Ears, Gangable, 12.5 cubic inch capacity

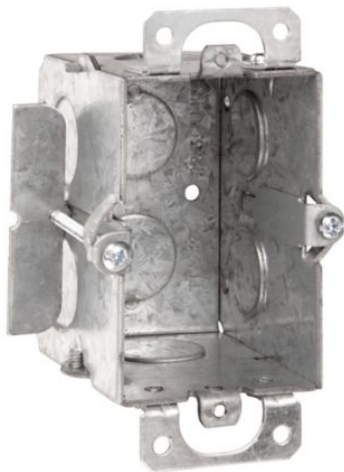

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton Crouse-Hinds series switch box	TP217
<b>UPC</b>	<b>Product Length/Depth</b>
786189102178	2 in
<b>Product Height</b>	<b>Product Width</b>
3 in	2.5 in
<b>Product Weight</b>	
0.64 lb	

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

## Product specifications

### Depth

2-1/2"

### Type

Gangable

### Capacity

12.5 cubic in

### Conduit/cable

Conduit (no clamps)

### End Knockouts

(1) 1/2 in

### Bottom Knockouts

(1) 1/2 in

### Material

Steel

### Special features

Ears

## Resources

### Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

### Certification reports

[Steel Switch Boxes UL certification](#)

[Steel Switch Boxes Canadian certification](#)

### Specifications and datasheets

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP217](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.




[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

# Eaton TP217

Catalog Number: TP217

Eaton Crouse-Hinds series Switch Box, (1) 1/2", Conduit (no clamps), 2-1/2", (1) 1/2", Steel, Ears, Gangable, 12.5 cubic inch capacity

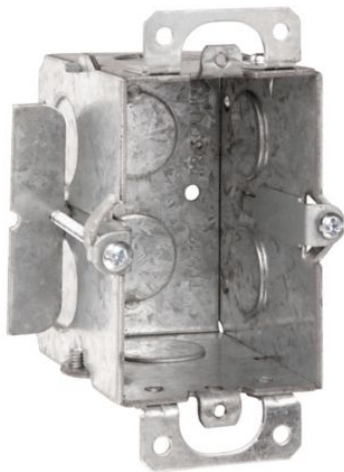

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton Crouse-Hinds series switch box	TP217
<b>UPC</b>	<b>Product Length/Depth</b>
786189102178	2 in
<b>Product Height</b>	<b>Product Width</b>
3 in	2.5 in
<b>Product Weight</b>	
0.64 lb	

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

## Product specifications

### Depth

2-1/2"

### Type

Gangable

### Capacity

12.5 cubic in

### Conduit/cable

Conduit (no clamps)

### End Knockouts

(1) 1/2 in

### Bottom Knockouts

(1) 1/2 in

### Material

Steel

### Special features

Ears

## Resources

### Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

### Certification reports

[Steel Switch Boxes UL certification](#)

[Steel Switch Boxes Canadian certification](#)

### Specifications and datasheets

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP217](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2025 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)