


# Eaton TP632

Catalog Number: TP632

Eaton Crouse-Hinds series Gang Box, (6) 1/2" and 3/4" concentric, VP, Conduit (no clamps), 2-1/2", (2) 1/2" and 3/4" concentric, Steel, Three-gang, (3) 1/2" and 3/4" concentric, Non-gangable, 46.5 cubic inch capacity

## General specifications

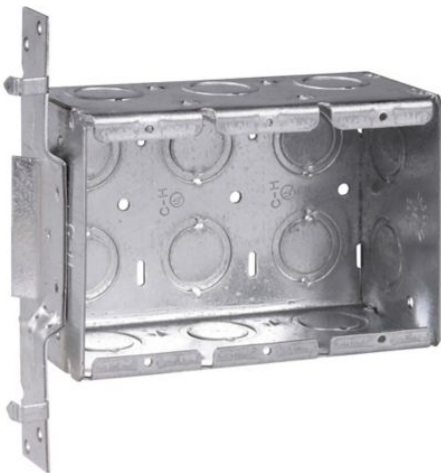

Product Name	Catalog Number
Eaton Crouse-Hinds series gang box	TP632
UPC	Product Length/Depth
786189106329	5.56 in
Product Height	Product Width
2.5 in	3.75 in
Product Weight	
1.43 lb	

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

## Product specifications

### Depth

2-1/2"

### Type

Non-gangable

### Number of gangs

Three-gang

### Capacity

46.5 cubic in

### Conduit/cable

Conduit (no clamps)

### Bracket style

VP

### End Knockouts

(2) 1/2 in and 3/4 in concentric

### Side knockouts

(3) 1/2 in and 3/4 in concentric

### Bottom Knockouts

(6) 1/2 in and 3/4 in concentric

### Material

Steel

## Resources

### Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

### Certification reports

[Steel Switch Boxes UL certification](#)

[Steel Switch Boxes Canadian certification](#)

### Specifications and datasheets

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP632](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

# Eaton TP632

Catalog Number: TP632

Eaton Crouse-Hinds series Gang Box, (6) 1/2" and 3/4" concentric, VP, Conduit (no clamps), 2-1/2", (2) 1/2" and 3/4" concentric, Steel, Three-gang, (3) 1/2" and 3/4" concentric, Non-gangable, 46.5 cubic inch capacity

## General specifications



Product Name	Catalog Number
Eaton Crouse-Hinds series gang box	TP632
UPC	Product Length/Depth
786189106329	5.56 in
Product Height	Product Width
2.5 in	3.75 in
Product Weight	
1.43 lb	

## Certifications and compliances

### Area classification

Ordinary/Non-Hazardous Locations

### Standards type

NEC/CEC

## Product specifications

### Depth

2-1/2"

### Type

Non-gangable

### Number of gangs

Three-gang

### Capacity

46.5 cubic in

### Conduit/cable

Conduit (no clamps)

### Bracket style

VP

### End Knockouts

(2) 1/2 in and 3/4 in concentric

### Side knockouts

(3) 1/2 in and 3/4 in concentric

### Bottom Knockouts

(6) 1/2 in and 3/4 in concentric

### Material

Steel

## Resources

### Catalogs

[Crouse-Hinds series Steel Switch Boxes catalog page](#)

### Certification reports

[Steel Switch Boxes UL certification](#)

[Steel Switch Boxes Canadian certification](#)

### Specifications and datasheets

[Steel Outlet Boxes for Electrical Systems](#)

[Eaton Specification Sheet - TP632](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)