


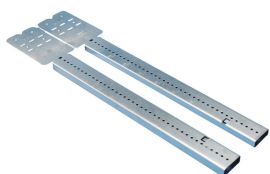

TELESCOPING BOX BRACKET 15 3/4"–25" STUD SPACE 1 1/2", 2 1/8", 2 1/2" BOX DEPTH

CATALOG NUMBER

TSGB1624



CERTIFICATIONS



FEATURES

Can mount multiple boxes

Notched and marked for easy identification and bending

Improved design with stamped inch markings and pilot holes accelerates precise box conduit mounting between studs

Pilot holes allow easy box attachment with a screwdriver

Requires only a screw gun to install

Can be mounted to face or inside of stud

Adjustable for non-standard stud spacing

Interlocking tab prevents accidental disassembly

Unique, one-piece, break apart design

PRODUCT ATTRIBUTES

Material: Steel

Finish: Pregalvanized
Stud Spacing: 15 3/4" - 25"
Box Depth: 1 1/2";2 1/8";2 1/2"

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America +1.800.753.9221 Option 1 – Customer Care Option 2 – Technical Support	Europe Netherlands: +31 800-0200135 France: +33 800 901 793	Europe Germany: 800 1890272 Other Countries: +31 13 5835404	APAC Shanghai: + 86 21 2412 1618/19 Sydney: +61 2 9751 8500
---	--	--	--