

AN ALL-INCLUSIVE SOLUTION

FOR ALL
YOUR
INDUSTRIAL
CHALLENGES



#LegrandImprovingLives

 **legrand**[®]



GO ALL IN

Go ALL IN with our full line of ready-to-install industrial solutions.

When it comes to choosing reliable electrical devices for your tough industrial jobs, you can go all in with Legrand, thanks to a rugged, robust product line that keeps on growing.

Whether your installation takes you to corrosive or wet environments, indoors or out, new facilities or old ones, you can count on us to

deliver what you and your customers need: fast installation, ergonomic operation, safety and unmatched reliability.

So, before you spec your next industrial job, take a look at our all-inclusive product line, and then **go all in with us, all the time.**



Provide more protection from more elements in more environments

Our expanded Rubber & Watertight product line means you can spec or install more ruggedly reliable plugs, connectors and receptacles in more places than ever. Available in Straight Blade and Turnlok® configurations, all of our NEMA and non-NEMA devices are built for long-lasting performance both indoors and out. Product features include:

- Thermoplastic elastomer construction withstands impact, chemicals, heat and corrosive conditions
- Terminal screws are backed-out and ready to wire, increasing productivity
- Quick-drive assembly screws allow for fast installation, saving time and money
- Large ribs on body for a superior grip when mating
- Keyed body and cover for easy alignment and assembly



Watertight Plugs, Connectors, Receptacles & Back Boxes

If the conditions are wet, moist or humid, the solution calls for our wide range of watertight devices.

NEMA CONFIGURATIONS — PLUGS AND CONNECTORS			
STRAIGHT BLADE		L16-20, L16-30	
	5-15, 5-20, 6-15, 6-20	L17-30	
	3P/3W 15A 125/250V	3P/3W 20A 125/250V	
	Non-NEMA	Non-NEMA	
TURNLOK		3P/3W 30A 125/250V	
	L5-15, L5-20, L5-30	Non-NEMA	
	L6-15, L6-20, L6-30	4P/4W 30A 3ø 120/208V	
	L7-15, L7-20, L7-30	Non-NEMA	
	L14-20, L14-30		
	L15-20, L15-30		
		BACK BOXES	
		Dead end and feed-through,	
		1/2"–1"	

ALL IN RUBBER & WATERTIGHT DEVICES

Rubber Plugs & Connectors

When dust, falling dirt and other particles are the enemy, you'll want our impressive line of industrial-strength rubber devices on your side.

NEMA CONFIGURATIONS — PLUGS AND CONNECTORS			
STRAIGHT BLADE		TURNLOK	
	5-15, 5-20, 6-15, 6-20	L5-15, L5-20, L5-30	
		L6-15, L6-20, L6-30	
		L7-15, L7-20, L7-30	
		L14-20, L14-30	
		L15-20, L15-30	
		L16-20, L16-30	
		L17-30	
		3P/3W 125/250V	
		Non-NEMA	

Corrosion-Resistant Plugs & Connectors

Corrosive elements like salt, sunlight, oils and other chemicals are no match for our rugged line of corrosion-resistant devices.

NEMA CONFIGURATIONS — PLUGS AND CONNECTORS			
STRAIGHT BLADE		TURNLOK	
	5-15	L5-15, L5-20, L5-30	
		L6-20, L6-30	
		L14-20, L14-30	
		2P/3W 50A 125V	
		Non-NEMA	
		2P/3W 50A 250VDC, 600VAC Non-NEMA	
		3P/4W 50A 125/250V Non-NEMA	
		3P/4W 50A 250VDC, 600VAC Non-NEMA	

Bring safety & productivity to the table

ALL IN FOOD & BEVERAGE




High-pressure washdowns. Particle build-up. Condensation. Corrosive substances. Food and beverage processing plants can be harsh, challenging environments. Fortunately, we have a full menu of electrical devices that keep things running smoothly while protecting people and equipment.



PORTABLE GFCI DEVICES



IEC PIN & SLEEVE DEVICES

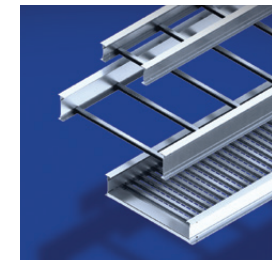

STAINLESS STEEL ITRAY LADDER TRAY



P&S MECHANICAL INTERLOCKS



Watertight Plugs & Connectors

- Thermoplastic elastomer body resists water, oils, lubricants and soaps while maintaining NEMA 4, 4X, 6, 6P, and IP65, 66, 67 ratings
- Ideal for washdown areas — rated watertight for 1,500 PSI high-pressure hose down
- Nickel-plated blades and contacts for long-lasting, superior corrosion resistance
- Watertight compression cord grips and a multipoint sealing system between the plug and connector ensures protection from water and contaminants



Cablofil® Wire Mesh Cable Trays

- Adapt to even the most complex configurations
- Designed to deliver maximum strength at minimum weight
- Ideal for small and hard-to-maneuver spaces
- Universal accessories for complete freedom in routing
- Also available in stainless steel



P&S Safety Switches

- Compact design reduces likelihood of impact damage
- Meets OSHA lockout/tagout provisions
- Nonconductive watertight, corrosion- and heat-resistant enclosure
- Corrosion-resistant stainless steel captive screws withstand abuse
- NEMA 4X/12 rated for harsh applications

PS30SS




FLEXCOR® WIRE MESH GRIPS

Devices that stand strong in adverse conditions

Manufacturing plant floors may not be pretty, but they've got to be productive. That's where our rugged workhorses come in. All of our industrial-grade solutions deliver industrial-strength electrical safety and reliability. That translates into maximum up time. All the time.

Manual Controllers

- Constructed of glass-reinforced thermoplastic
- Heavy-duty zinc-plated steel strap
- High horsepower rating of 20hp
- Oversized silver alloy contacts

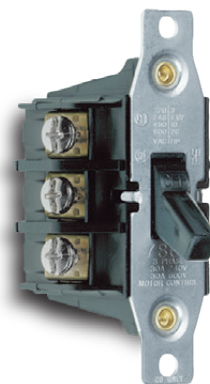

7803



Portable GFCIs

- Rugged polycarbonate housing stands up to impacts and hard use
- Water-resistant design for wet and corrosive indoor/outdoor environments
- Automatic reset ensures continuous power for pumps, portable signs, lights and engine heaters
- Watertight rubber cord grommets seal the GFCI from the environment

1594PC2M



Heavy-Duty Ground Continuity Monitoring (GCM) Plugs & Connectors

- Designed for tough industrial environments
- Continuous monitoring enhances safety for people and equipment
- Dual, bright LED indicators with 360 degree visibility
- Chemical- and impact-resistant housing
- Internal dust shield keeps terminals free of contaminants

L630PGCM, L630CGCM



TURNLOK®
PLUGS & CONNECTORS



FLEXCOR®
WIRE MESH GRIPS



CABLOFIL®
WIRE MESH TRAYS



EXTRA-HARD-USE
STRAIGHT BLADE PLUGS
& CONNECTORS



PORTABLE OUTLET
BOXES



Peerless protection from the elements

ALL IN MARINE



With their constant exposure to the elements, shipyards, docks and ports aren't only tough places to work, but tough on the electrical devices that help keep things moving. Not surprisingly, our industrial-strength solutions are designed to hold their own in any marine-based environment, doing their part to keep people and products safe.



Cam-Type Devices

- Delivers reliable temporary power when and where it's needed
- Protective thermoplastic housing resists water and corrosion
- Sturdy, vibration- and impact-resistant construction
- Heavy-duty brass contacts provide consistent conductivity

PS40MBBK, PS40FBBK



IEC PIN & SLEEVE DEVICES



PORTABLE GFCI DEVICES



RUBBER & WATERTIGHT PLUGS & CONNECTORS



EXTRA-HARD-USE STRAIGHT BLADE PLUGS & CONNECTORS



TURNLOK[®] LOCKING PLUGS & CONNECTORS



Corrosion-Resistant Plugs & Connectors

- Nylon housing provides impact and chemical resistance
- Rugged two-piece cord grip provides more uniform cord retention
- Internal dust shield keeps terminals free of contaminants
- Heavy-duty nickel-plated brass alloy blades and contacts resist heat, prevent corrosion and provide excellent conductivity
- Cord-grip screws recessed to protect against screwdriver head slippage

CR6360, CR6361

Fusible Mechanical Interlocks

- Extra-rugged construction for wet, humid and corrosive environments
- Corrosion-resistant stainless steel captive screws ensure watertight seal
- NEMA 4X and 12 watertight-rated
- Hinged access door with window enables fast fuse change-outs

PS430FMR12W

Reliable workhorses for harsh and hazardous terrain

ALL IN OIL & GAS



As the creator of the first GFCI receptacle, we know electrical safety. And that's a valuable trait when you're a leading global manufacturer of electrical solutions for petrochemical producers. From temporary power to ground fault protection to high-amperage connectors, we offer everything you need to ensure electrical safety in volatile environments.




Cablofil® Wire Mesh Cable Trays

- Adapt to even the most complex configurations
- Designed to deliver maximum strength at maximum capacity
- Ideal for small and hard-to-maneuver spaces
- Universal accessories for complete freedom in routing

Itray Ladder Tray

- I-beam side-rail design ensures a lighter, stronger tray
- Features the industry's strongest I-beam rungs
- Wraparound cover clamps ideal for outdoor applications
- Smooth side-rail design creates natural path for cables

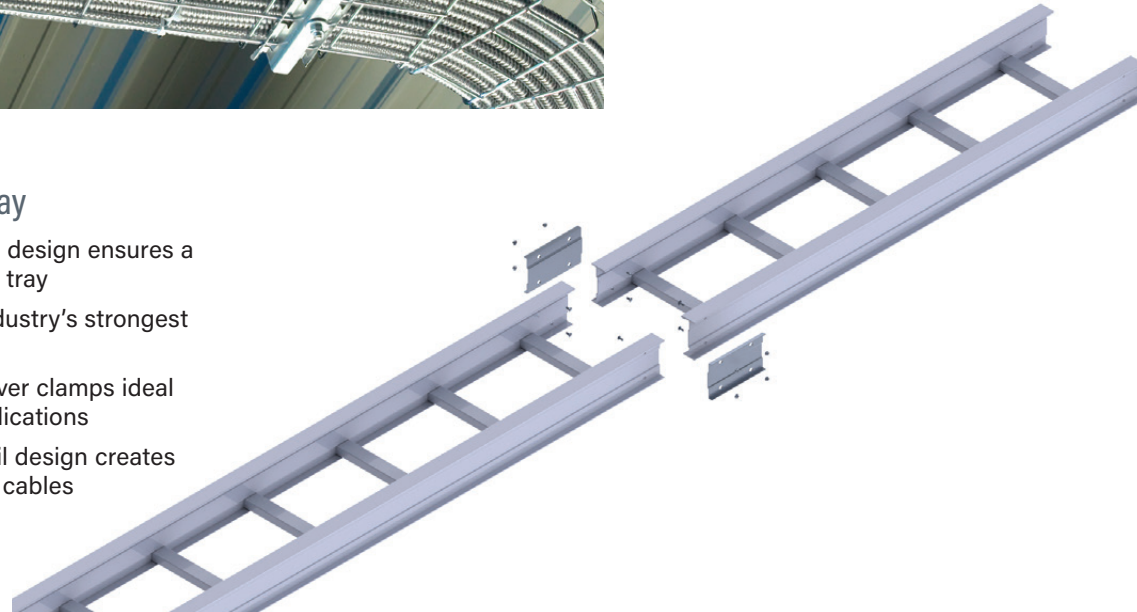

Manual Controllers

- Impact-, chemical- and temperature-resistant
- Nickel-plated brass mounting for superior strength and corrosion resistance
- Oversized toggle operation ideal for gloved hands
- Rated for hazardous locations

7813EX



IEC PIN & SLEEVE DEVICES



PORTABLE GFCI DEVICES



CAM-TYPE DEVICES



RUBBER AND WATER-TIGHT RECEPTACLES



FLEXCOR® WIRE MESH GRIPS

Corrosion-proof solutions for confined spaces

ALL IN MINING




Aboveground and underground mines are some of the most unpredictable and dangerous places on earth. They're also the most dependent on reliable sources of electricity. That's where we come in. From temporary power that keeps the lights on, to portable GFCI devices that keep miners safe, our portfolio of rugged electrical solutions runs deep.



PORTABLE GFCI DEVICES




RUBBER PLUGS & CONNECTORS

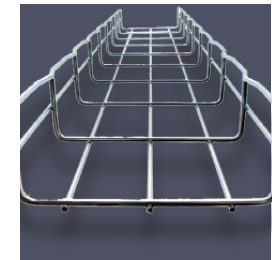

CABLOFIL®
WIRE MESH TRAYS



TURNLOK®
PLUGS & CONNECTORS

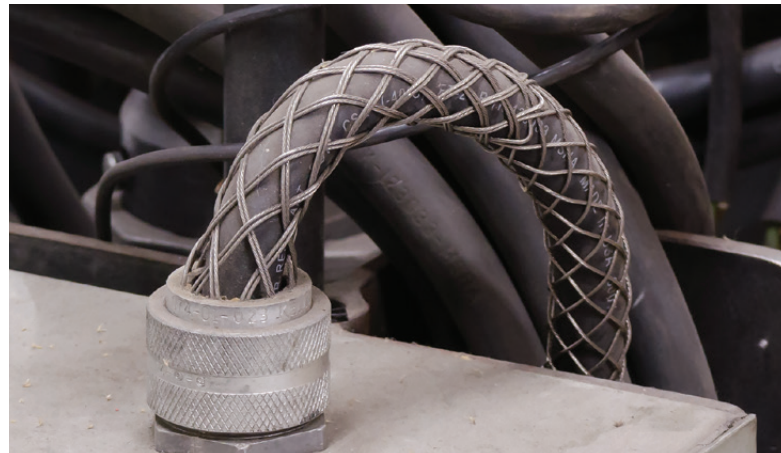

Flexcor® Wire Mesh Grips

- Noncorrosive double-weave stainless steel mesh absorbs stress and vibration
- Die-cast aluminum fitting with watertight seal protects connections from cable stress in damp applications
- Deluxe grips designed for use in hazardous locations
- Ideal for rugged and moist outdoor environments

CG610



Manual Controllers

- Impact-, chemical- and temperature-resistant
- Nickel-plated brass mounting for superior strength and corrosion resistance
- Oversized toggle operation ideal for gloved hands

7863R



IEC Pin & Sleeve Watertight Devices

- Maximum durability for minimum downtime
- Quick, no-guesswork wiring
- Chemical-resistant thermoplastic construction
- Shrouded, nickel-plated, solid-brass pins provide corrosion protection and excellent conductivity

PS430R7W, PS430P7W



Portable Outlet Boxes

- Industrial-grade boxes deliver power when and where it's needed
- Impact-, chemical-, temperature- and fatigue-resistant design
- Reliable GFCI protection for wet areas
- Available in single- and two-gang sizes

High in water resistance, low in total cost of ownership

ALL IN WATER & WASTEWATER



They say electricity and water don't mix, but in wastewater treatment facilities, it's essential. In fact, a reliable source of power isn't just important for workers, but for everyone in the community. We're proud that many of our electrical solutions are used to ensure the reliable flow of electrical power — and clean water.



P&S Safety Switches

- Compact design reduces likelihood of impact damage
- Meets OSHA lockout/tagout provisions
- Nonconductive, watertight, corrosion- and heat-resistant enclosure
- Corrosion-resistant stainless steel captive screws withstand abuse
- NEMA 4X/12 rated for harsh applications

PS100SSAX

IEC Pin & Sleeve Devices

- Maximum durability for minimum downtime
- Quick, no-guesswork wiring
- Chemical-resistant thermoplastic construction
- Shrouded, nickel-plated, solid-brass pins provide corrosion protection and excellent conductivity

PS460R7W, PS460P7W, PSBB601W




PW HDG Trays

- Long-span heavy-duty trays are ideal for outdoor pipe bridges
- Designed with structural I-beam side rails
- Ladder, trough and solid-bottom designs
- Handle extremely heavy loads



WATERTIGHT PLUGS,
CONNECTORS &
RECEPTACLES

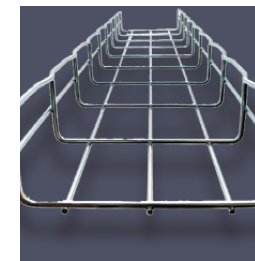

CABLOFIL® HDG & SS
WIRE MESH TRAYS



CORROSION-RESISTANT
PLUGS & CONNECTORS



NON-FUSIBLE
MECHANICAL INTERLOCKS



MANUAL CONTROLLERS

Make every connection count

ALL IN TEMPORARY POWER



When it comes to temporary power applications, every connection must count. From outdoor special events to busy construction sites, you need electrical solutions that help you power up and connect without disruptions. Our suite of temporary power solutions will help keep your power operations running smoothly.



PORTABLE GFCI DEVICES



PORTABLE OUTLET BOXES



EXTRA-HARD-USE
STRAIGHT BLADE PLUGS
& CONNECTORS



IEC PIN & SLEEVE
DEVICES



50A Turnlok® Plugs & Connectors

- Faster installation with simple push, twist and lock body assembly
- Durable impact and corrosion-resistant Nylon 66 Shell material
- Same-plane hex head terminations



Turnlok® Locking Plugs & Connectors

- Quick-thread assembly screws install 3X faster
- Double dovetail design for superior protection
- Industrial-strength brass alloy plug blades
- External cord grips provide visual of safe and proper cord retention



Flexcor® Strain Relief

- Noncorrosive double-weave stainless steel mesh absorbs stress and vibration
- Die-cast aluminum fitting with watertight seal protects connections from cable stress in damp applications
- Deluxe grips designed for use in hazardous locations
- Ideal for rugged and moist outdoor environments



legrand.us



youtube.com/legrand



linkedin.com/legrand



facebook.com/Legrand

© 2025 Legrand All Rights Reserved BR1850 07/25

For additional technical or application-specific information, call
800-223-4185 or visit our website at www.legrand.us/PassandSeymour.
We're eager to put our expertise to work for you.

Electrical Wiring Systems
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us

