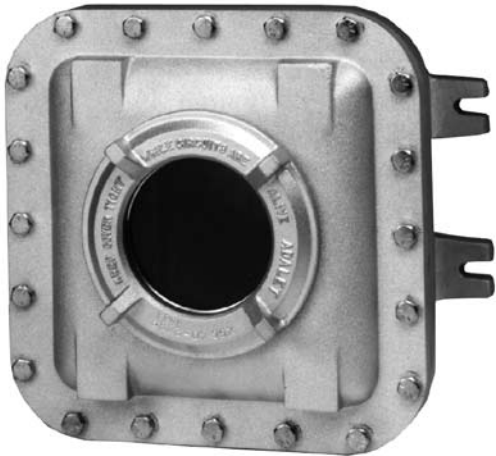
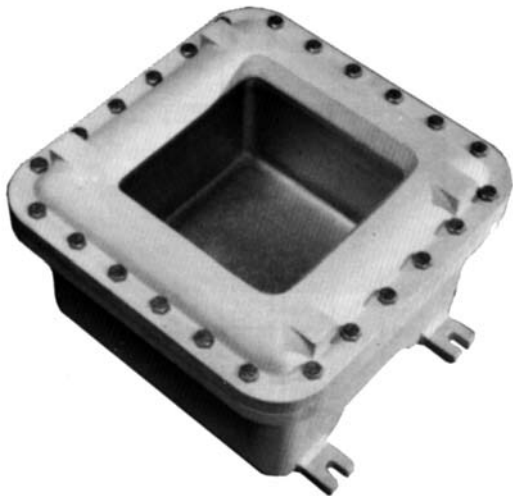


# Glass Windows

**CIRCULAR WINDOW**

Circular Window	Window Viewing Area Diameter	Overall Window Cover Diameter	Min Enclosure Inside Width / Length	Thread
XGC 10	1 1/8	3	8	2 1/2-16
XGC 20	1 5/16	4 1/8	9	3 3/8-12
XGC 30	3	5 3/8	9	4 3/4 - 12
XGC 40	4	6 3/8	9	5 1/2 - 12
XGC 52	5 1/4	7 7/8	10	7 1/8 - 12
XGC 66	6 1/16	10 3/8	16	9 1/8 - 12
XGC 80	8	12 1/8	18	10 7/8 - 8


- NOTES**
1. All dimensions are in inches.
  2. Glass window catalog number includes XCE cover machining and installation.
  3. For TYPE 4/IP66 option add suffix "N4".
  4. To order glass windows for field installations, add suffix SLF to XGC catalog no.
  5. Consult factory for closer spacing requirements, multiple windows or combinations of operators and windows.

**RECTANGULAR WINDOW**

Rectangular Window	Window Viewing Area Diameter	Min Enclosure Inside Width	Min Enclosure Inside Length
XGW 0303	3 X 3	8	8
XGW 0305	3 X 5	8	10
XGW 0307	3 X 7	8	12
XGW 0505	5 X 5	10	10
XGW 0509	5 X 9	10	14
XGW 0707	7 X 7	12	12
XGW 0713	7 X 13	12	18
XGW 0909	9 X 9	14	14
XGW 1111	11 X 11	16	16
XGW 1313	13 X 13	18	18

- NOTES**
1. All dimensions are in inches
  2. Glass window catalog number includes installation and pattern modifications.
  3. For TYPE 4 option add suffix "N4".
  4. Consult factory for special viewing area requirement, closer spacing and to combine windows with other window sizes or operators.
  5. Any size window can be ordered in any combination between 3" and 13" – Consult Factory.


# Glass Windows

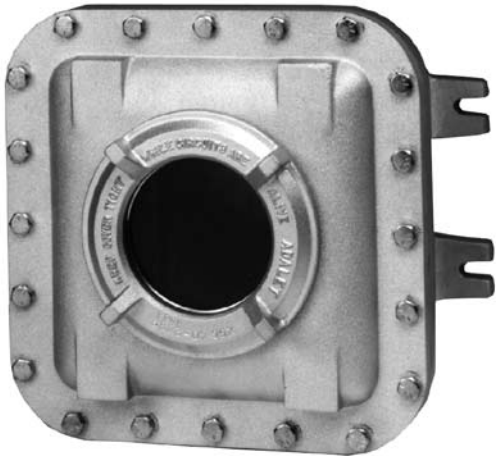

## CIRCULAR WINDOW

Circular Window	Window Viewing Area Diameter	Overall Window Cover Diameter	Min Enclosure Inside Width / Length	Thread
XGC 10	1 1/8	3	8	2 1/2-16
XGC 20	1 5/16	4 1/8	9	3 3/8-12
XGC 30	3	5 3/8	9	4 3/4 - 12
XGC 40	4	6 3/8	9	5 1/2 - 12
XGC 52	5 1/4	7 7/8	10	7 1/8 - 12
XGC 66	6 1/16	10 3/8	16	9 1/8 - 12
XGC 80	8	12 1/8	18	10 7/8 - 8

- NOTES**
1. All dimensions are in inches.
  2. Glass window catalog number includes XCE cover machining and installation.
  3. For TYPE 4/IP66 option add suffix "N4".
  4. To order glass windows for field installations, add suffix SLF to XGC catalog no.
  5. Consult factory for closer spacing requirements, multiple windows or combinations of operators and windows.

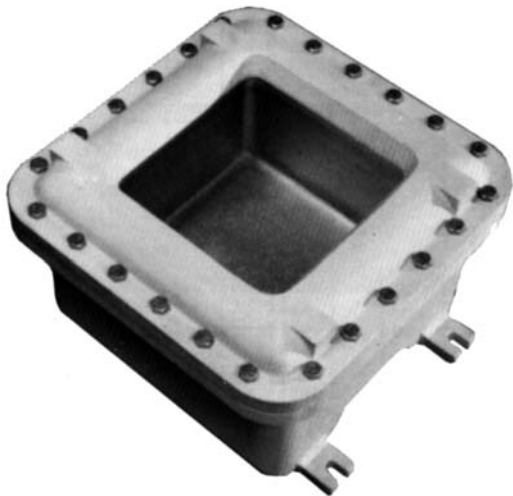

## RECTANGULAR WINDOW

Rectangular Window	Window Viewing Area Diameter	Min Enclosure Inside Width	Min Enclosure Inside Length
XGW 0303	3 X 3	8	8
XGW 0305	3 X 5	8	10
XGW 0307	3 X 7	8	12
XGW 0505	5 X 5	10	10
XGW 0509	5 X 9	10	14
XGW 0707	7 X 7	12	12
XGW 0713	7 X 13	12	18
XGW 0909	9 X 9	14	14
XGW 1111	11 X 11	16	16
XGW 1313	13 X 13	18	18

- NOTES**
1. All dimensions are in inches
  2. Glass window catalog number includes installation and pattern modifications.
  3. For TYPE 4 option add suffix "N4".
  4. Consult factory for special viewing area requirement, closer spacing and to combine windows with other window sizes or operators.
  5. Any size window can be ordered in any combination between 3" and 13" – Consult Factory.