


# Specifications



Photo is representative

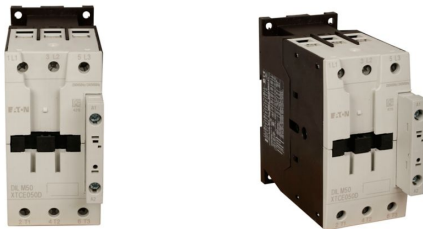

## Eaton XTCE050DS1A

Eaton XT IEC contactor, 50A, Side-mounted, 110 Vac 50 Hz, 120 Vac 60 Hz, 1NO-1NC, 50A, Frame D, 55 mm, 50-60 Hz, 3, 7.5, 10/15, 20, 40, 50 hp(1/3PH@115, 200, 230/200, 230, 460, 575 V), Three-pole, Screw terminals, FVNR

### General specifications

<b>PRODUCT NAME</b>	Eaton XT IEC contactor
<b>CATALOG NUMBER</b>	XTCE050DS1A
<b>UPC</b>	786685365114
<b>PRODUCT LENGTH/DEPTH</b>	1 in
<b>PRODUCT HEIGHT</b>	1 in
<b>PRODUCT WIDTH</b>	1 in
<b>PRODUCT WEIGHT</b>	1 lb
<b>WARRANTY</b>	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
<b>CERTIFICATIONS</b>	UL Listed CSA Certified EN 60947 IEC 60947

## Product specifications

AMPERAGE RATING	50A
HP RATING - MAX	3, 7.5, 10/ 15, 20, 40, 50 hp (1/3PH @115,200,230/200,230,460,575 V)
NUMBER OF POLES	Three-pole
TYPE	Full voltage non-reversing contactor
FREQUENCY RATING	50-60 Hz
FRAME SIZE	55 mm
TERMINALS	Screw terminals
COIL	110-120 Vac, 50/60 Hz
COIL VOLTAGE	110-120 Vac, 50/60 Hz
CONTACT CONFIGURATION	1 NO, 1 NC
CONTINUOUS AMPERE RATING	50 A
SERIES	XT IEC
OPERATION	Non-reversing

## Resources

CATALOGS	<a href="#">Motor Control and Protection, IEC Contactors and Starters, Volume 5, Tab 1</a>
SPECIFICATIONS AND DATASHEETS	<a href="#">Eaton Specification Sheet - XTCE050DS1A</a>
WARRANTY GUIDES	<a href="#">Selling Policy 25-000 - Distribution and Control Products and Services</a>

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



### Eaton Corporation plc

Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2025 Eaton. All Rights Reserved.


Follow us on social media to get the latest product and support information.



# Specifications



Photo is representative

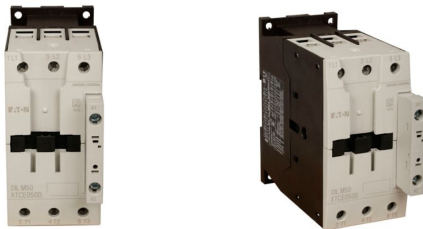

## Eaton XTCE050DS1A

Eaton XT IEC contactor, 50A, Side-mounted, 110 Vac 50 Hz, 120 Vac 60 Hz, 1NO-1NC, 50A, Frame D, 55 mm, 50-60 Hz, 3, 7.5, 10/15, 20, 40, 50 hp(1/3PH@115, 200, 230/200, 230, 460, 575 V), Three-pole, Screw terminals, FVNR

### General specifications

<b>PRODUCT NAME</b>	Eaton XT IEC contactor
<b>CATALOG NUMBER</b>	XTCE050DS1A
<b>UPC</b>	786685365114
<b>PRODUCT LENGTH/DEPTH</b>	1 in
<b>PRODUCT HEIGHT</b>	1 in
<b>PRODUCT WIDTH</b>	1 in
<b>PRODUCT WEIGHT</b>	1 lb
<b>WARRANTY</b>	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
<b>CERTIFICATIONS</b>	UL Listed CSA Certified EN 60947 IEC 60947

## Product specifications

AMPERAGE RATING	50A
HP RATING - MAX	3, 7.5, 10/ 15, 20, 40, 50 hp (1/3PH @115,200,230/200,230,460,575 V)
NUMBER OF POLES	Three-pole
TYPE	Full voltage non-reversing contactor
FREQUENCY RATING	50-60 Hz
FRAME SIZE	55 mm
TERMINALS	Screw terminals
COIL	110-120 Vac, 50/60 Hz
COIL VOLTAGE	110-120 Vac, 50/60 Hz
CONTACT CONFIGURATION	1 NO, 1 NC
CONTINUOUS AMPERE RATING	50 A
SERIES	XT IEC
OPERATION	Non-reversing

## Resources

CATALOGS	<a href="#">Motor Control and Protection, IEC Contactors and Starters, Volume 5, Tab 1</a>
SPECIFICATIONS AND DATASHEETS	<a href="#">Eaton Specification Sheet - XTCE050DS1A</a>
WARRANTY GUIDES	<a href="#">Selling Policy 25-000 - Distribution and Control Products and Services</a>

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



### Eaton Corporation plc

Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2025 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.

