


# Specifications



Photo is representative

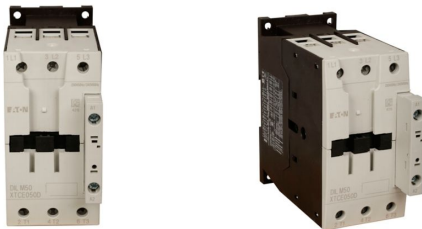

## Eaton XTCE050DS1A

Eaton XT IEC contactor, 50A, Side-mounted, 110 Vac 50 Hz, 120 Vac 60 Hz, 1NO-1NC, 50A, Frame D, 55 mm, 50-60 Hz, 3, 7.5, 10/15, 20, 40, 50 hp(1/3PH@115, 200, 230/200, 230, 460, 575 V), Three-pole, Screw terminals, FVNR

### General specifications

PRODUCT NAME	Eaton XT IEC contactor
CATALOG NUMBER	XTCE050DS1A
UPC	786685365114
PRODUCT LENGTH/DEPTH	1 in
PRODUCT HEIGHT	1 in
PRODUCT WIDTH	1 in
PRODUCT WEIGHT	1 lb
WARRANTY	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
CERTIFICATIONS	UL Listed CSA Certified EN 60947 IEC 60947

## Product specifications

AMPERAGE RATING	50A
HP RATING - MAX	3, 7.5, 10/ 15, 20, 40, 50 hp (1/3PH @115,200,230/200,230,460,575 V)
NUMBER OF POLES	Three-pole
TYPE	Full voltage non-reversing contactor
FREQUENCY RATING	50-60 Hz
FRAME SIZE	55 mm
TERMINALS	Screw terminals
COIL	110-120 Vac, 50/60 Hz
COIL VOLTAGE	110-120 Vac, 50/60 Hz
CONTACT CONFIGURATION	1 NO, 1 NC
CONTINUOUS AMPERE RATING	50 A
SERIES	XT IEC
OPERATION	Non-reversing

## Resources

CATALOGS	<a href="#">Motor Control and Protection, IEC Contactors and Starters, Volume 5, Tab 1</a>
SPECIFICATIONS AND DATASHEETS	<a href="#">Eaton Specification Sheet - XTCE050DS1A</a>
WARRANTY GUIDES	<a href="#">Selling Policy 25-000 - Distribution and Control Products and Services</a>

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



### Eaton Corporation plc

Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2025 Eaton. All Rights Reserved.

Follow us on social media to get the latest product and support information.

