
BURNDY Catalog Number

YA312LH93TN

UPC Number

7818100857388

Description

CUHYSEALUG 350KCMIL TIN

PLATED

Status

Active

Web Use

BURNDY Product Line

Dimensional

Tongue Angle	Straight
B Length (Fraction)	1-1/8
Length (in)	6.00
Barrell Style	Shrouded
Bolt Hole Size (in)	0.52
Barrel Type	Standard
Thickness	0.18
E - in	1.75

General

Number of Holes	2
Product Description	Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

Conductor(s)

Copper Solid Size (Range)	N/A
Copper Stranded (Range)	250 kcmil

Physical

Type of Plating	Tin - Electro Plated
Bolt Hole Size	1/2
Plated (Yes or No)	Y
Product Material	Copper

Approvals / Certifications

UL Listed	N
CSA Certified	N
ROHS Compatible	Compliant
UL Recognized	N
CULUS	N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

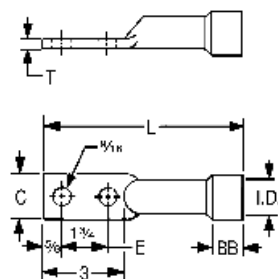
47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM

Monday - Friday
Phone: 800-346-4175


BURNDY Catalog Number

YA312LH93TN

UPC Number

7818100857388

Description

CUHYSEALUG 350KCMIL TIN

PLATED

Status

Active

Web Use

BURNDY Product Line

Dimensional

Tongue Angle	Straight
B Length (Fraction)	1-1/8
Length (in)	6.00
Barrell Style	Shrouded
Bolt Hole Size (in)	0.52
Barrel Type	Standard
Thickness	0.18
E - in	1.75

General

Number of Holes	2
Product Description	Tin-plated, CU 2-hole NEMA compression terminal with shrouded barrel for terminating insulated CU conductor to transformers and other equipment, 6 IN L

Conductor(s)

Copper Solid Size (Range)	N/A
Copper Stranded (Range)	250 kcmil

Physical

Type of Plating	Tin - Electro Plated
Bolt Hole Size	1/2
Plated (Yes or No)	Y
Product Material	Copper

Approvals / Certifications

UL Listed	N
CSA Certified	N
ROHS Compatible	Compliant
UL Recognized	N
CULUS	N

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
Manchester NH 03109

Hours: 8:00 AM - 5:00 PM

Monday - Friday
Phone: 800-346-4175