

BURNDY Catalog Number
UPC Number
Description
Status

YA6C
 7818105017577
 6AWG 1/4STUD LONG
 Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle Straight
 Length (in) 1.81
 Tongue Type Standard
 Barrell Style Chamfered
 Bolt Hole Size (in) 0.27
 Barrel Type Long
 Thickness 0.09
 B Length (in) 1.12
 Pad Width (in) 0.41
 Strip Length 1 3/16

General

Number of Holes 1
 Product Description Copper Compression Lug, 1 Hole w/o Inspection Window, 6 AWG, 1/4" Stud, Long Barrel, Belled End, Tin Plated

Conductor(s)

Flex (Class G) Size - Range N/A
 Flex (Class H) Size - Range N/A
 Flex (Class I) Size - Range N/A
 Copper Solid Size (Range) N/A
 DLO Size (Range) N/A
 Copper Stranded (Range) 6 AWG

Physical

Type of Plating Tin
 Bolt Hole Size 1/4
 Color Code Blue
 Plated (Yes or No) Y
 Index Number 7
 Product Material Copper

Approvals / Certifications

UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards UL468A-468B

Documentation

For further technical assistance, please contact us


BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175

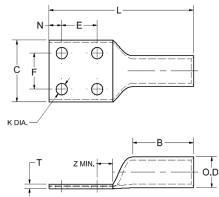

BURNDY Catalog Number
UPC Number
Description
Status

YA6C
 7818105017577
 6AWG 1/4STUD LONG
 Active

Web Use
 BURNDY Product Line

Dimensional

Tongue Angle Straight
 Length (in) 1.81
 Tongue Type Standard
 Barrell Style Chamfered
 Bolt Hole Size (in) 0.27
 Barrel Type Long
 Thickness 0.09
 B Length (in) 1.12
 Pad Width (in) 0.41
 Strip Length 1 3/16

General

Number of Holes 1
 Product Description Copper Compression Lug, 1 Hole w/o Inspection Window, 6 AWG, 1/4" Stud, Long Barrel, Belled End, Tin Plated

Conductor(s)

Flex (Class G) Size - Range N/A
 Flex (Class H) Size - Range N/A
 Flex (Class I) Size - Range N/A
 Copper Solid Size (Range) N/A
 DLO Size (Range) N/A
 Copper Stranded (Range) 6 AWG

Physical

Type of Plating Tin
 Bolt Hole Size 1/4
 Color Code Blue
 Plated (Yes or No) Y
 Index Number 7
 Product Material Copper

Approvals / Certifications

UL Listed Y
 CSA Certified Y
 ROHS Compatible Compliant
 UL Recognized N
 CULUS N
 Industry Standards UL468A-468B

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

47 East Industrial Park Drive
 Manchester NH 03109

BURNDY Technical Services

47 East Industrial Park Drive
 Manchester NH 03109

Hours: 8:00 AM - 5:00 PM
 Monday - Friday
 Phone: 800-346-4175