




YGHP34C34 Figure 6 Compression Grounding Connector

By Burndy
Catalog # YGHP34C34

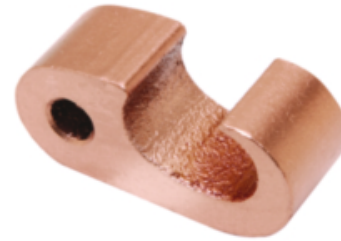

Cu Compression Ground Rod Connector, 350 Kcmil - 500 Kcmil, 5/8" - 3/4" Rod Dia.

Application

For Direct Burial In Earth And Concrete

General

Connector Type	Tap
Die Index	1011
EU RoHS Indicator	Yes
Material	Copper
Oxide Inhibitor Type	Penetrox E
Physical Attribute - Number of Crimps Required	3
Plated	N
Plating Type	Unplated
Prefilled Oxide Inhibitor	Y
Sub Brand	HYTAP
Trade Name	HYTAP™
Type	Taps
UPC	781810220986
UPC 12 Digit	7818102209866

Dimensions

Dimension - B Length fraction	1-1/10 in
Dimension - B Length inch	1.10 in

Conductor Related

Conductor - Copper Str Run	250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Run Range	250 kcmil-500 kcmil
Conductor - Copper Str Tap	350 kcmil;400 kcmil;450 kcmil;500 kcmil
Conductor - Copper Str Tap Range	350 kcmil-500 kcmil
Conductor - Rebar Run	5 ;6
Conductor - Rebar Run Range	5 -6
Conductor - Rod Run	5/8 in;3/4 in
Conductor - Rod Run Range	5/8 in-3/4 in

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	Yes
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	Direct Burial
Standards - Industry Standards Met	<ul style="list-style-type: none">UL467IEEE 837
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	20
Minimum Pack Quantity	1
Pallet Quantity	2960

Product Assets

[3D Models - YGHP34C34_MODEL-IGES](#)
[3D Models - YGHP34C34_MODEL-PDF](#)
[3D Models - YGHP34C34_MODEL-STEP](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - sd082473-01](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
BRDY-YGHP34C34-SPEC-EN | REV 8/2023

