


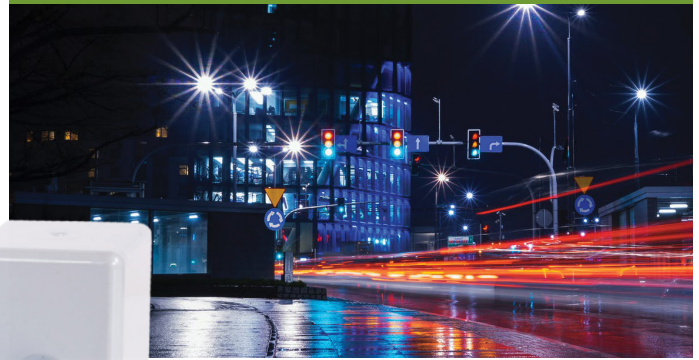





# TORK®

## Z SERIES PHOTOCONTROLS



ITEM	MODEL NUMBER	DESCRIPTION	REPLACE
	<b>5237-UL</b> Turnlock <b>(Meets Utility Standards)</b>	LED Photocontrol 105-305 volt, 1000-watt Tungsten, 1800VA Ballast 4 amps 510 MOV Surge protection	<b>Intermatic</b> ELC4536
	<b>ZTL124</b> Turnlock <b>(Utility Grade)</b>	<b>Zero-Cross LED</b> Photocontrol 105-305 volt, 1000-watt Tungsten, 1800VA Ballast 8 amps 510 MOV Surge protection	<b>Intermatic</b> (Same Control) EK4536 LED4536-SC
	<b>ZB124WP</b> Button with Plate  <b>ZSS124</b> Stem Swivel	<b>Electronic Photocontrol Zero-Cross LED</b> 105-305 volt, 1000-watt Tungsten, 1800VA Ballast MOV Surge protection	<b>Intermatic</b> EK4336S Button with Plate EK4236S Stem Swivel
	<b>TORK UL Listed for LED</b> <b>3010</b> Button with Plate (120 volt Only) <b>2001</b> Stem Swivel (120 volt) <b>2002</b> Stem Swivel (208-277 volt)	Thermal Photocontrol 120 volt, 2000-watt Tungsten, 1800VA Ballast  208-277 volt, 3470-4620-watt Tungsten, 2080-2770VA Ballast	<b>Intermatic Not UL Listed for LED</b> K4321C Button with Plate (120 volt Only) K4121C Stem Swivel (120 volt) K4123C Stem Swivel (208-277 volt)



ITEM	MODEL NUMBER	DESCRIPTION	REPLACE
	<b>1109A</b> (Nema 1)  <b>1109A-O</b> (Nema 3)	24-Hour Time Switch Multi-Voltage, 120-277 volt, 40 amp Rated  Easier to Read Dial and Operation Sealed Motor	<b>Intermatic Switches</b>  T101 & T101R T102 & T102R T103 & T103R T104 & T104R  <b>Replaces (8) SKU's</b>
	<b>1109AM-IAP</b> (Mech Only)	24-Hour Time Switch Multi-Voltage 120-277 volt, 40 amp Rated  Replaces Intermatic Mechanism into Existing Intermatic Enclosures	<b>Intermatic Mech</b>  T101M T102M T103M T104M <b>Replaces (4) SKU's</b>
	<b>EWZ201C</b> (Nema 3R)	7-Day Digital Time Switch, 2 Channel, 120-277 volt, 30 amp Rated  Astronomic, Holiday, Operates Electronically and Mechanically held Contactors  Plastic, Indoor/ Outdoor Enclosure	<b>Intermatic Switches</b>  ET8215C / ET8215CR ET2825C / ET2825CR  <b>Replaces (4) SKU's</b> (Available in single circuit)  <b>EWZ120 (No Holidays)</b> <b>Not CA Title 24</b>
	<b>TORK SS703Z</b>	7-Day Programmable Astronomic In-Wall  120/277 volt, 15 amp Rated  Single Pole Single Throw (SPST)  Super Capacitor Back-Up  No Neutral Required, 3-Way	<b>Intermatic</b>  ST01C Battery Backup Battery Operates the Relay